


## ARMT-3 Clean Water Applications *(cont'd.)*

- 2-1/2" NPT Brass Screw Plug
- Copper Sheath Elements
- High Watt Density (46 - 53 W/in<sup>2</sup>)
- 3 - 18 kW
- Integral Thermostat (DPST)
- 120, 208, 240 and 480 Volt,  
1 and 3 Phase
- Moisture Resistant/Explosion  
Resistant Terminal Enclosure



*E2 — Dimensions (Inches)*

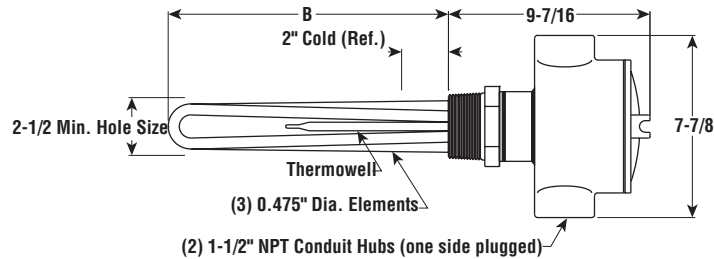

**FASTShip**

Same-day shipping on stock item  
orders received before 4 pm CST.  
3-day shipping on assembly-stock items.

### Specifications and Ordering Information

							T2 — Temperature (60 - 250°F)			T1 — Temperature (0 - 100°F)		
kW	Volts	Phase	W/in <sup>2</sup>	No. Elem.	DIM B (In.)	Wt. (Lbs.)	Model	Stock	PCN	Model	Stock	PCN
<b>E2 Moisture Resistant/Explosion Resistant</b>												
12	208	1	46	3	32-5/16	18	ARMT-31205E2T2 <sup>1</sup>	AS	321234	ARMT-31205E2T1 <sup>1</sup>	NS	321242
12	208	3	46	3	32-5/16	18	ARMT-31205E2T2	AS	321277	ARMT-31205E2T1	NS	321285
12	240	1	46	3	32-5/16	18	<b>ARMT-31205E2T2<sup>1</sup></b>	<b>S</b>	<b>321314</b>	ARMT-31205E2T1 <sup>1</sup>	NS	321322
12	240	3	46	3	32-5/16	18	ARMT-31205E2T2	AS	321357	ARMT-31205E2T1	NS	321365
12	480	1	46	3	32-5/16	18	ARMT-31205E2T2	AS	321390	ARMT-31205E2T1	NS	321402
12	480	3	46	3	32-5/16	18	ARMT-31205E2T2	AS	321437	ARMT-31205E2T1	NS	321445
15	208	1	46	3	39-3/4	19	ARMT-31505E2T2 <sup>1</sup>	AS	321470	ARMT-31505E2T1 <sup>1</sup>	NS	321488
15	208	3	46	3	39-3/4	19	ARMT-31505E2T2	AS	321517	ARMT-31505E2T1	NS	321525
15	240	1	46	3	39-3/4	19	ARMT-31505E2T2 <sup>1</sup>	AS	321550	ARMT-31505E2T1 <sup>1</sup>	NS	321568
15	240	3	46	3	39-3/4	19	ARMT-31505E2T2	AS	321592	ARMT-31505E2T1	NS	321605
15	480	1	46	3	39-3/4	19	ARMT-31505E2T2	AS	321630	ARMT-31505E2T1	NS	321648
15	480	3	46	3	39-3/4	19	ARMT-31505E2T2	AS	321672	ARMT-31505E2T1	NS	321680
18	208	1	46	3	47-1/4	20	ARMT-31805E2T2 <sup>1</sup>	AS	311212	ARMT-31805E2T1 <sup>1</sup>	NS	311220
18	208	3	46	3	47-1/4	20	ARMT-31805E2T2 <sup>1</sup>	AS	321710	ARMT-31805E2T1 <sup>1</sup>	NS	321728
18	240	1	46	3	47-1/4	20	ARMT-31805E2T2 <sup>1</sup>	AS	321752	ARMT-31805E2T1 <sup>1</sup>	NS	321760
18	240	3	46	3	47-1/4	20	ARMT-31805E2T2	AS	321795	ARMT-31805E2T1	NS	321808
18	480	1	46	3	47-1/4	20	ARMT-31805E2T2	AS	321832	ARMT-31805E2T1	NS	321840
18	480	3	46	3	47-1/4	20	ARMT-31805E2T2	AS	321875	ARMT-31805E2T1	NS	321883

**Stock Status:** S = stock NS = non-stock  
**To Order**—Specify model, volts, phase, kW, PCN and quantity.

1. Not cCSA<sub>US</sub>® Certified (Exceeds 48 Amps).