

Immersion

MT-3 Clean Water Applications


- 2-1/2" NPT Brass Screw Plug
- Copper Sheath Elements
- High Watt Density (46 - 53 W/in²)
- 3 - 18 kW
- Without Thermostat
- 120, 208, 240 and 480 Volt, 1 and 3 Phase
- General Purpose, Moisture Resistant/Explosion Resistant Terminal Enclosure or Moisture Resistant

FASTShip


Same-day shipping on stock item orders received before 4 pm CST. 3-day shipping on assembly-stock items.

Specifications and Ordering Information


E1 — Dimensions (Inches)

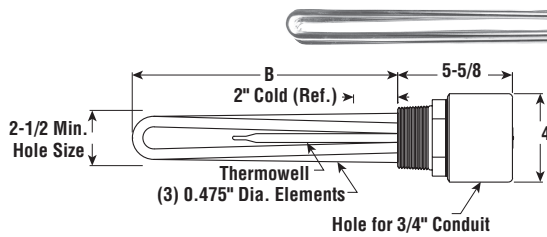

E2 — Dimensions (Inches)

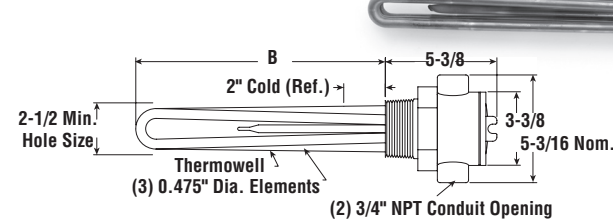

E4TP — Dimensions (Inches)

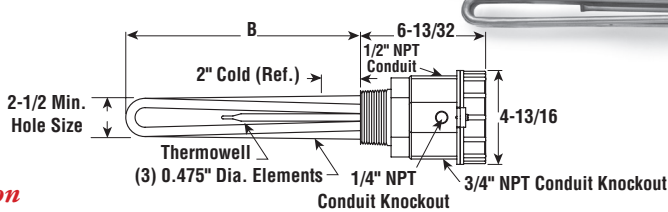

SCREW PLUG

						E1 General Purpose ¹				E2 Moisture Resistant/ Explosion Resistant ²				E4 Moisture Resistant			
kW	Volts	Phase	W/in ²	No. Elem.	DIM B (In.)	Model	Stock	PCN	Wt. (Lbs.)	Model	Stock	PCN	Wt. (Lbs.)	Model	Stock	PCN	Wt. (Lbs.)
3	120	1	51	3	7-3/8	MT-330A	NS	191396	5	MT-330E2	NS	310800	8	MT-330E4TP	NS	063861	5
3	240	1	51	3	7-3/8	MT-330A	NS	191409	5	MT-330E2	NS	288809	8	MT-330E4TP	NS	063870	5
3	480	1	51	3	7-3/8	MT-330A	NS	191417	5	MT-330E2	NS	310818	8	MT-330E4TP	NS	063888	5
3	240	3	51	3	7-3/8	MT-330A	S	191433	5	MT-330E2	NS	288817	8	MT-330E4TP	NS	063896	5
3	480	3	51	3	7-3/8	MT-330A	S	191441	5	MT-330E2	NS	322288	8	MT-330E4TP	NS	063909	5
3	208	1	51	3	7-3/8	MT-330A	NS	322245	5	MT-330E2	NS	322253	8	MT-330E4TP	NS	063917	5
3	208	3	51	3	7-3/8	MT-330A	NS	322261	5	MT-330E2	NS	322270	8	MT-330E4TP	NS	063925	5
3.75	120	1	52	3	8-7/8	MT-337A	NS	191450	6	MT-337E2	NS	310826	9	MT-337E4TP	NS	063933	6
3.75	240	1	52	3	8-7/8	MT-337A	NS	191468	6	MT-337E2	NS	288825	9	MT-337E4TP	NS	063941	6
3.75	480	1	52	3	8-7/8	MT-337A	NS	191476	6	MT-337E2	NS	310834	9	MT-337E4TP	NS	063950	6
3.75	240	3	52	3	8-7/8	MT-337A	NS	191492	6	MT-337E2	NS	288833	9	MT-337E4TP	NS	063968	6
3.75	480	3	52	3	8-7/8	MT-337A	S	191505	6	MT-337E2	NS	322333	9	MT-337E4TP	NS	063976	6
3.75	208	1	52	3	8-7/8	MT-337A	NS	322296	6	MT-337E2	NS	322309	9	MT-337E4TP	NS	063984	6
3.75	208	3	52	3	8-7/8	MT-337A	NS	322317	6	MT-337E2	NS	322325	9	MT-337E4TP	NS	063992	6
4.5	120	1	48	3	11-3/8	MT-345A	NS	191513	6	MT-345E2	NS	310842	9	MT-345E4TP	NS	064004	6
4.5	240	1	48	3	11-3/8	MT-345A	S	191521	6	MT-345E2	NS	288841	9	MT-345E4TP	NS	064012	6
4.5	480	1	48	3	11-3/8	MT-345A	NS	191530	6	MT-345E2	NS	288868	9	MT-345E4TP	NS	064020	6
4.5	240	3	48	3	11-3/8	MT-345A	S	191556	6	MT-345E2	NS	288850	9	MT-345E4TP	NS	064039	6
4.5	480	3	48	3	11-3/8	MT-345A	S	191564	6	MT-345E2	NS	288876	9	MT-345E4TP	NS	064047	6
4.5	208	1	48	3	11-3/8	MT-345A	NS	322341	6	MT-345E2	NS	322350	9	MT-345E4TP	NS	064055	6
4.5	208	3	48	3	11-3/8	MT-345A	S	322368	6	MT-345E2	NS	322376	9	MT-345E4TP	NS	064063	6
6	120	1	48	3	17-3/8	MT-360A	NS	191572	8	MT-360E2	NS	310850	11	MT-360E4TP	NS	064071	8
6	240	1	48	3	17-3/8	MT-360A	NS	191580	8	MT-360E2	NS	288884	11	MT-360E4TP	NS	064080	8
6	480	1	48	3	17-3/8	MT-360A	NS	191599	8	MT-360E2	NS	288905	11	MT-360E4TP	NS	064098	8
6	240	3	48	3	17-3/8	MT-360A	S	191610	8	MT-360E2	NS	288892	11	MT-360E4TP	NS	064100	8
6	480	3	48	3	17-3/8	MT-360A	S	191628	8	MT-360E2	NS	322392	11	MT-360E4TP	NS	064119	8
6	208	1	48	3	17-3/8	MT-360A	NS	322384	8	MT-360E2	NS	288913	11	MT-360E4TP	NS	064127	8
6	208	3	48	3	17-3/8	MT-360A	NS	322405	8	MT-360E2	NS	322413	11	MT-360E4TP	NS	064135	8
7.5	240	1	53	3	19-1/8	MT-375A	NS	191636	8	MT-375E2	NS	288921	11	MT-375E4TP	NS	064143	8
7.5	480	1	53	3	19-1/8	MT-375A	NS	191644	8	MT-375E2	NS	288948	11	MT-375E4TP	NS	064151	8
7.5	240	3	53	3	19-1/8	MT-375A	S	191652	8	MT-375E2	NS	288930	11	MT-375E4TP	NS	064160	8
7.5	480	3	53	3	19-1/8	MT-375A	S	191660	8	MT-375E2	NS	288956	11	MT-375E4TP	NS	064178	8
7.5	208	1	53	3	19-1/8	MT-375A	NS	322421	8	MT-375E2	NS	322430	11	MT-375E4TP	NS	064186	8
7.5	208	3	53	3	19-1/8	MT-375A	NS	322448	8	MT-375E2	NS	322456	11	MT-375E4TP	NS	064194	8
9	240	1	47	3	24-1/2	MT-390A	NS	191679	12	MT-390E2	NS	288964	15	MT-390E4TP	NS	064207	12
9	480	1	47	3	24-1/2	MT-390A	NS	191687	12	MT-390E2	NS	288980	15	MT-390E4TP	NS	064215	12
9	240	3	47	3	24-1/2	MT-390A	S	191695	12	MT-390E2	NS	288972	15	MT-390E4TP	NS	064223	12
9	480	3	47	3	24-1/2	MT-390A	S	191708	12	MT-390E2	S	288999	15	MT-390E4TP	NS	064231	12
9	208	1	47	3	24-1/2	MT-390A	NS	322464	12	MT-390E2	NS	322472	15	MT-390E4TP	NS	064240	12
9	208	3	47	3	24-1/2	MT-390A	NS	322480	12	MT-390E2	NS	322499	15	MT-390E4TP	NS	064258	12