


ARMTS-2 Process Water Applications *(cont'd.)*



- 2" NPT Stainless Steel Passivated Screw Plug
- Stainless Steel Passivated Sheath Elements
- High Watt Density (43 - 51 W/In²)
- 2 - 15 kW
- Integral Thermostat (DPST)
- 208, 240 and 480 Volt, Single Phase
- Moisture Resistant/Explosion Resistant Terminal Enclosure

E2 — Dimensions (Inches)

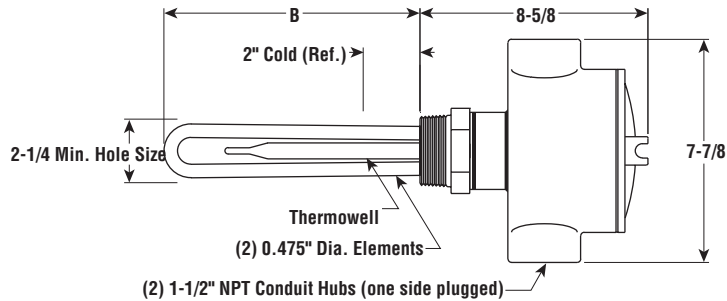

Specifications and Ordering Information

							T2 — Temperature (60 - 250°F)			T1 — Temperature (0 - 100°F)		
kW	Volts	Phase	W/In ²	Elem.	DIM B (In.)	Wt. (Lbs.)	Model	Stock	PCN	Model	Stock	PCN
E2 Moisture Resistant/Explosion Resistant												
2	208	1	51	2	7-1/2	12	ARMTS-2205-3E2T2	NS	187442	ARMTS-2205-3E2T1	NS	187450
2	240	1	51	2	7-1/2	12	ARMTS-2205-3E2T2	NS	184161	ARMTS-2205-3E2T1	NS	184209
2	480	1	51	2	7-1/2	12	ARMTS-2205-3E2T2	NS	184170	ARMTS-2205-3E2T1	NS	184217
2.5	240	1	47	2	9	13	ARMTS-2255E2T2	NS	184241	ARMTS-2255E2T1	NS	184284
2.5	480	1	47	2	9	13	ARMTS-2255E2T2	NS	184250	ARMTS-2255E2T1	NS	184292
3	208	1	43	2	11-1/2	13	ARMTS-2305E2T2	NS	187485	ARMTS-2305E2T1	NS	187493
3	240	1	43	2	11-1/2	13	ARMTS-2305E2T2	NS	184321	ARMTS-2305E2T1	NS	184364
3	480	1	43	2	11-1/2	13	ARMTS-2305E2T2	NS	184330	ARMTS-2305E2T1	NS	184372
4	208	1	44	2	17-1/2	13	ARMTS-2405E2T2	NS	187522	ARMTS-2405E2T1	NS	187530
4	240	1	44	2	17-1/2	13	ARMTS-2405E2T2	NS	184401	ARMTS-2405E2T1	NS	184444
4	480	1	44	2	17-1/2	13	ARMTS-2405E2T2	NS	184410	ARMTS-2405E2T1	NS	184452
5	208	1	45	2	19	14	ARMTS-2505E2T2	NS	187565	ARMTS-2505E2T1	NS	187573
5	240	1	45	2	19	14	ARMTS-2505E2T2	NS	184487	ARMTS-2505E2T1	NS	184524
5	480	1	45	2	19	14	ARMTS-2505E2T2	NS	184495	ARMTS-2505E2T1	NS	184532
6	208	1	46	2	24-1/2	14	ARMTS-2605E2T2	NS	187602	ARMTS-2605E2T1	NS	187610
6	240	1	46	2	24-1/2	14	ARMTS-2605E2T2	NS	184567	ARMTS-2605E2T1	NS	184604
6	480	1	46	2	24-1/2	14	ARMTS-2605E2T2	NS	184575	ARMTS-2605E2T1	NS	184612
7	240	1	46	2	27-1/2	15	ARMTS-2705E2T2	NS	184647	ARMTS-2705E2T1	NS	184680
7	480	1	46	2	27-1/2	15	ARMTS-2705E2T2	NS	184655	ARMTS-2705E2T1	NS	184698
10	208	1	46	2	40	16	ARMTS-21005E2T2	NS	187645	ARMTS-21005E2T1	NS	187653
10	240	1	46	2	40	16	ARMTS-21005E2T2	NS	184727	ARMTS-21005E2T1	NS	184760
10	480	1	46	2	40	16	ARMTS-21005E2T2	NS	184735	ARMTS-21005E2T1	NS	184778
12	240	1	46	2	48	17	ARMTS-21205E2T2 ¹	NS	310682	ARMTS-21205E2T1 ¹	NS	310703
12	480	1	46	2	48	17	ARMTS-21205E2T2	NS	310690	ARMTS-21205E2T1	NS	310711
15	240	1	50	2	54	18	ARMTS-21505E2T2 ¹	NS	310762	ARMTS-21505E2T1 ¹	NS	310789
15	480	1	50	2	54	18	ARMTS-21505E2T2	NS	310770	ARMTS-21505E2T1	NS	310797

Stock Status: S = stock NS = non-stock
To Order—Specify model, volts, phase, kW, PCN and quantity.

1. Not CSA NRTL/C Certified (Exceeds 48 Amps).



Same-day shipping on stock item orders received before 4 pm CST.
 3-day shipping on assembly-stock items.