


## ARMTS-3

### Process Water Applications



- 2-1/2" NPT Stainless Steel Passivated Screw Plug
- Stainless Steel Passivated Sheath Elements
- High Watt Density (46 - 53 W/In<sup>2</sup>)
- 3 - 18 kW
- Integral Thermostat (DPST)
- 208, 240 and 480 Volt, Three Phase
- General Purpose Terminal Enclosure

*E1 — Dimensions (Inches)*

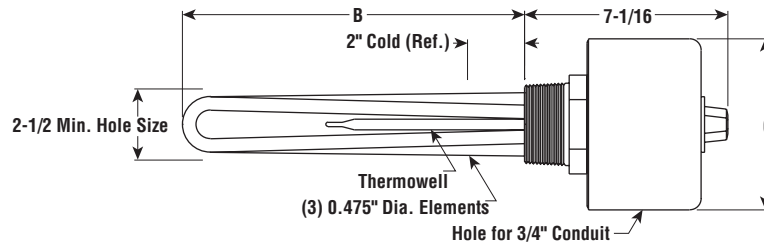

### Specifications and Ordering Information

							T2 — Temperature (60 - 250°F)			T1 — Temperature (0 - 100°F)		
kW	Volts	Phase	W/In <sup>2</sup>	Elem.	DIM B (In.)	Wt. (Lbs.)	Model	Stock	PCN	Model	Stock	PCN
<b>E1 General Purpose</b>												
3	208	3	51	3	7	8	ARMTS-3305T2	NS	187100	ARMTS-3305T1	NS	187119
3	240	3	51	3	7	8	ARMTS-3305T2	NS	184786	ARMTS-3305T1	NS	184823
3	480	3	51	3	7	8	ARMTS-3305T2	NS	184794	ARMTS-3305T1	NS	184831
4.5	208	3	48	3	11	8	ARMTS-3455T2	NS	187143	ARMTS-3455T1	NS	187151
4.5	240	3	48	3	11	8	ARMTS-3455T2	NS	184866	ARMTS-3455T1	NS	184903
4.5	480	3	48	3	11	8	ARMTS-3455T2	NS	184874	ARMTS-3455T1	NS	184911
6	208	3	48	3	17	9	ARMTS-3605T2	NS	187186	ARMTS-3605T1	NS	187194
6	240	3	48	3	17	9	ARMTS-3605T2	NS	184946	ARMTS-3605T1	NS	184989
6	480	3	48	3	17	9	ARMTS-3605T2	NS	184955	ARMTS-3605T1	NS	184997
7.5	208	3	53	3	18-1/2	10	ARMTS-3755T2	NS	187223	ARMTS-3755T1	NS	187231
7.5	240	3	53	3	18-1/2	10	ARMTS-3755T2	NS	185025	ARMTS-3755T1	NS	185068
7.5	480	3	53	3	18-1/2	10	ARMTS-3755T2	NS	185033	ARMTS-3755T1	NS	185076
9	208	3	47	3	24	10	ARMTS-3905T2	NS	187266	ARMTS-3905T1	NS	187274
9	240	3	47	3	24	10	ARMTS-3905T2	NS	185105	ARMTS-3905T1	NS	185148
9	480	3	47	3	24	10	ARMTS-3905T2	NS	185113	ARMTS-3905T1	NS	185156
12	208	3	46	3	32	11	ARMTS-3120T2	NS	187305	ARMTS-3120T1	NS	187311
12	240	3	46	3	32	11	ARMTS-3120T2	NS	185180	ARMTS-3120T1	NS	185228
12	480	3	46	3	32	11	ARMTS-3120T2	NS	185199	ARMTS-3120T1	NS	185236
15	208	3	46	3	39-1/2	12	ARMTS-3150T2	NS	187346	ARMTS-3150T1	NS	187354
15	240	3	46	3	39-1/2	12	ARMTS-3150T2	NS	185260	ARMTS-3150T1	NS	185308
15	480	3	46	3	39-1/2	12	ARMTS-3150T2	NS	185279	ARMTS-3150T1	NS	185316
18	208	3	51	3	47	13	ARMTS-3180T2 <sup>1</sup>	NS	187389	ARMTS-3180T1 <sup>1</sup>	NS	187397
18	240	3	51	3	47	13	ARMTS-3180T2	NS	185340	ARMTS-3180T1	NS	185383
18	480	3	51	3	47	13	ARMTS-3180T2	NS	185359	ARMTS-3180T1	NS	185391

**Stock Status:** S = stock NS = non-stock  
**To Order**—Specify model, volts, phase, kW, PCN and quantity.

1. Not UL Listed or CSA Certified (Exceeds 48 Amps).



Same-day shipping on stock item orders received before 4 pm CST.  
 3-day shipping on assembly-stock items.