


## AREMTI-3 Solution Water Applications


- 2" NPT Stainless Steel Screw Plug
- INCOLOY® Sheath Elements
- High Watt Density (45 W/In<sup>2</sup>)
- 3 - 18 kW
- Integral Thermostat (DPST)
- 120, 240 and 480 Volt, Three Phase
- General Purpose or Moisture Resistant/Explosion Resistant Terminal Enclosure



**E1 — Dimensions (Inches)**

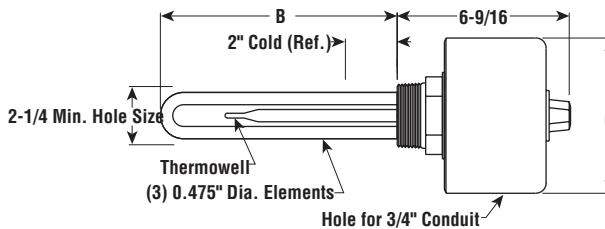

**E2 — Dimensions (Inches)**

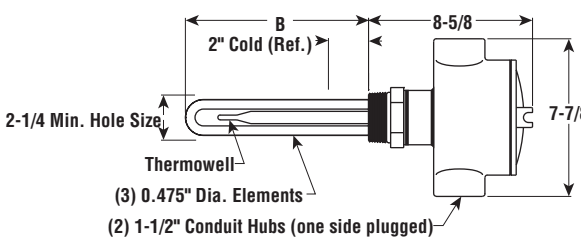

SCREW PLUG

### Specifications and Ordering Information

kW	Volts	Phase	W/In <sup>2</sup>	No. Elem.	DIM B (In.)	Wt. (Lbs.)	T2 — Temperature (60 - 250°F)			T1 — Temperature (0 - 100°F)		
							Model	Stock	PCN	Model	Stock	PCN
<b>E1 General Purpose<sup>1</sup></b>												
3	240	3	45	3	7-3/4	7	AREMTI-3305T2	NS	097990	AREMTI-3305T1	NS	032213
3	480	3	45	3	7-3/4	7	AREMTI-3305T2	NS	098001	AREMTI-3305T1	NS	032221
6	240	3	45	3	17-3/4	8	<b>AREMTI-3605T2</b>	<b>S</b>	<b>099160</b>	AREMTI-3605T1	NS	032230
6	480	3	45	3	17-3/4	8	<b>AREMTI-3605T2</b>	<b>S</b>	<b>099178</b>	AREMTI-3605T1	NS	032248
9	240	3	45	3	24-7/8	9	<b>AREMTI-3905T2</b>	<b>S</b>	<b>099186</b>	AREMTI-3905T1	NS	032256
9	480	3	45	3	24-7/8	9	AREMTI-3905T2	NS	099194	AREMTI-3905T1	NS	032264
12	240	3	45	3	32-7/16	10	AREMTI-31205T2	NS	099207	AREMTI-31205T1	NS	032272
12	480	3	45	3	32-7/16	10	<b>AREMTI-31205T2</b>	<b>S</b>	<b>099215</b>	AREMTI-31205T1	NS	032280
15	240	3	45	3	40-3/8	11	AREMTI-31505T2	NS	099223	AREMTI-31505T1	NS	032299
15	480	3	45	3	40-3/8	11	<b>AREMTI-31505T2</b>	<b>S</b>	<b>099231</b>	AREMTI-31505T1	NS	032301
18	240	3	45	3	47-7/8	12	AREMTI-31805T2	NS	099240	AREMTI-31805T1	NS	032310
18	480	3	45	3	47-7/8	12	<b>AREMTI-31805T2</b>	<b>S</b>	<b>099258</b>	AREMTI-31805T1	NS	032328
<b>E2 Moisture Resistant/Explosion Resistant<sup>2</sup></b>												
3	240	3	45	3	7-3/4	12	AREMTI-3305E2T2	NS	032336	AREMTI-3305E2T1	NS	032459
3	480	3	45	3	7-3/4	12	AREMTI-3305E2T2	NS	032344	AREMTI-3305E2T1	NS	032467
6	240	3	45	3	17-3/4	13	AREMTI-3605E2T2	NS	032352	AREMTI-3605E2T1	NS	032475
6	480	3	45	3	17-3/4	13	AREMTI-3605E2T2	NS	032360	AREMTI-3605E2T1	NS	032483
9	240	3	45	3	24-7/8	14	AREMTI-3905E2T2	NS	032379	AREMTI-3905E2T1	NS	032491
9	480	3	45	3	24-7/8	14	AREMTI-3905E2T2	NS	032387	AREMTI-3905E2T1	NS	032504
12	240	3	45	3	32-7/16	15	AREMTI-31205E2T2	NS	032395	AREMTI-31205E2T1	NS	032512
12	480	3	45	3	32-7/16	15	AREMTI-31205E2T2	NS	032408	AREMTI-31205E2T1	NS	032520
15	240	3	45	3	40-3/8	16	AREMTI-31505E2T2	NS	032416	AREMTI-31505E2T1	NS	032539
15	480	3	45	3	40-3/8	16	AREMTI-31505E2T2	NS	032424	AREMTI-31505E2T1	NS	032547
18	240	3	45	3	47-7/8	17	AREMTI-31805E2T2	NS	032432	AREMTI-31805E2T1	NS	032555
18	480	3	45	3	47-7/8	17	AREMTI-31805E2T2	NS	032440	AREMTI-31805E2T1	NS	032563

**Stock Status:** S = stock NS = non-stock  
**To Order**—Specify model, volts, phase, kW, PCN and quantity.

1. Heaters with General Purpose Enclosures are UL Listed and CSA Certified.
2. Heaters with Moisture Resistant/Explosion Resistant Enclosures are <sup>C</sup>CSA<sub>US</sub>® Certified.

**FASTShip**

Same-day shipping on stock item orders received before 4 pm CST. 3-day shipping on assembly-stock items.