


ARMTI-3 Solution Water Applications



SCREW PLUG

- 2-1/2" NPT Stainless Steel Screw Plug
- INCOLOY® Sheath Elements
- High Watt Density (46 - 53 W/in²)
- 3 - 18 kW
- Integral Thermostat (DPST)
- 240 and 480 Volt, Three Phase
- General Purpose Terminal Enclosure

E1 — Dimensions (Inches)

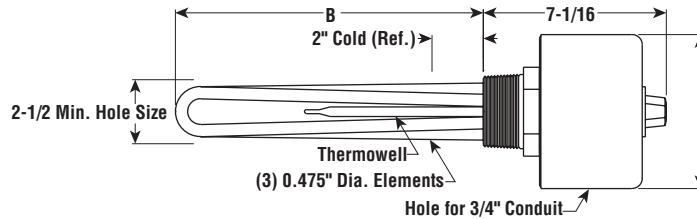

Specifications and Ordering Information

							T2 — Temperature (60 - 250°F)			T1 — Temperature (0 - 100°F)		
kW	Volts	Phase	W/in ²	No. Elem.	DIM B (in.)	Wt. (Lbs.)	Model	Stock	PCN	Model	Stock	PCN
E1 General Purpose¹												
3	240	3	51	3	7	8	ARMTI-3305T2	NS	188787	ARMTI-3305T1	NS	188795
3	480	3	51	3	7	8	ARMTI-3305T2	NS	188824	ARMTI-3305T1	NS	188832
4.5	240	3	48	3	11	8	ARMTI-3455T2	NS	188867	ARMTI-3455T1	NS	188875
4.5	480	3	48	3	11	8	ARMTI-3455T2	NS	188904	ARMTI-3455T1	NS	188912
6	240	3	48	3	17-3/8	9	ARMTI-3605T2	NS	188947	ARMTI-3605T1	NS	188955
6	480	3	48	3	17-3/8	9	ARMTI-3605T2	NS	188980	ARMTI-3605T1	NS	188998
7.5	240	3	53	3	19	10	ARMTI-3755T2	NS	189026	ARMTI-3755T1	NS	189034
7.5	480	3	53	3	19	10	ARMTI-3755T2	NS	189069	ARMTI-3755T1	NS	189077
9	240	3	47	3	24-3/8	10	ARMTI-3905T2	NS	189106	ARMTI-3905T1	NS	189114
9	480	3	47	3	24-3/8	10	ARMTI-3905T2	NS	189149	ARMTI-3905T1	NS	189157
12	240	3	46	3	32-1/4	11	ARMTI-3120T2	NS	189181	ARMTI-3120T1	NS	189190
12	480	3	46	3	32-1/4	11	ARMTI-3120T2	NS	189229	ARMTI-3120T1	NS	189237
15	240	3	46	3	39-7/8	12	ARMTI-3150T2	NS	189261	ARMTI-3150T1	NS	189270
15	480	3	46	3	39-7/8	12	ARMTI-3150T2	NS	189309	ARMTI-3150T1	NS	189317
18	240	3	51	3	47-3/8	13	ARMTI-3180T2	NS	189341	ARMTI-3180T1	NS	189350
18	480	3	51	3	47-3/8	13	ARMTI-3180T2	NS	189384	ARMTI-3180T1	NS	189392

Stock Status: S = stock NS = non-stock
To Order—Specify model, volts, phase, kW, PCN and quantity.

FASTShip[™]

1. Heaters with General Purpose Enclosures are UL Listed and CSA Certified.
2. Heaters with Moisture Resistant/Explosion Resistant Enclosures are cCSA_{US}® Certified.

Same-day shipping on stock item orders received before 4 pm CST.
 3-day shipping on assembly-stock items.