


ARMTI-3 Solution Water Applications *(cont'd.)*



- 2-1/2" NPT Stainless Steel Screw Plug
- INCOLOY® Sheath Elements
- High Watt Density (46 - 53 W/in²)
- 3 - 18 kW
- Integral Thermostat (DPST)
- 240 and 480 Volt, Three Phase
- Moisture Resistant/Explosion Resistant Terminal Enclosure

E2 — Dimensions (Inches)

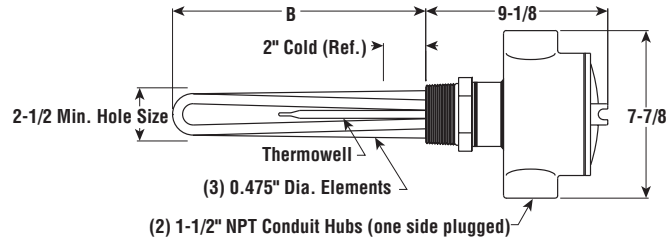

Specifications and Ordering Information

							T2 — Temperature (60 - 250°F)			T1 — Temperature (0 - 100°F)		
kW	Volts	Phase	W/in ²	No. Elem.	DIM B (In.)	Wt. (Lbs.)	Model	Stock	PCN	Model	Stock	PCN
E2 Moisture Resistant/Explosion Resistant²												
3	240	3	51	3	7	13	ARMTI-3305E2T2	NS	188808	ARMTI-3305E2T1	NS	188816
3	480	3	51	3	7	13	ARMTI-3305E2T2	NS	188840	ARMTI-3305E2T1	NS	188859
4.5	240	3	48	3	11	13	ARMTI-3455E2T2	NS	188883	ARMTI-3455E2T1	NS	188891
4.5	480	3	48	3	11	13	ARMTI-3455E2T2	NS	188920	ARMTI-3455E2T1	NS	188939
6	240	3	48	3	17-3/8	14	ARMTI-3605E2T2	NS	188963	ARMTI-3605E2T1	NS	188971
6	480	3	48	3	17-3/8	14	ARMTI-3605E2T2	NS	189000	ARMTI-3605E2T1	NS	189018
7.5	240	3	53	3	19	15	ARMTI-3755E2T2	NS	189042	ARMTI-3755E2T1	NS	189050
7.5	480	3	53	3	19	15	ARMTI-3755E2T2	NS	189085	ARMTI-3755E2T1	NS	189093
9	240	3	47	3	24-3/8	15	ARMTI-3905E2T2	NS	189122	ARMTI-3905E2T1	NS	189130
9	480	3	47	3	24-3/8	15	ARMTI-3905E2T2	NS	189165	ARMTI-3905E2T1	NS	189173
12	240	3	46	3	32-1/4	16	ARMTI-3120E2T2	NS	189202	ARMTI-3120E2T1	NS	189210
12	480	3	46	3	32-1/4	16	ARMTI-3120E2T2	NS	189245	ARMTI-3120E2T1	NS	189253
15	240	3	46	3	39-7/8	17	ARMTI-3150E2T2	NS	189288	ARMTI-3150E2T1	NS	189296
15	480	3	46	3	39-7/8	17	ARMTI-3150E2T2	NS	189325	ARMTI-3150E2T1	NS	189333
18	240	3	51	3	47-3/8	18	ARMTI-3180E2T2	NS	189368	ARMTI-3180E2T1	NS	189376
18	480	3	51	3	47-3/8	18	ARMTI-3180E2T2	NS	189405	ARMTI-3180E2T1	NS	189413

Stock Status: S = stock NS = non-stock
To Order—Specify model, volts, phase, kW, PCN and quantity.

1. Heaters with General Purpose Enclosures are UL Listed and CSA Certified.
2. Heaters with Moisture Resistant/Explosion Resistant Enclosures are cCSA_{US}® Certified.

FASTShip™

Same-day shipping on stock item orders received before 4 pm CST.
 3-day shipping on assembly-stock items.