


AREMTS-3

Severely Corrosive Solution Applications


- 2" NPT Stainless Steel Passivated Screw Plug
- Stainless Steel Passivated Sheath Elements
- Low Watt Density (15 W/In²)
- 1 - 6 kW
- Integral Thermostat (DPST)
- 240 and 480 Volt, Three Phase
- General Purpose or Moisture Resistant/Explosion Resistant Terminal Enclosure



E1 — Dimensions (Inches)

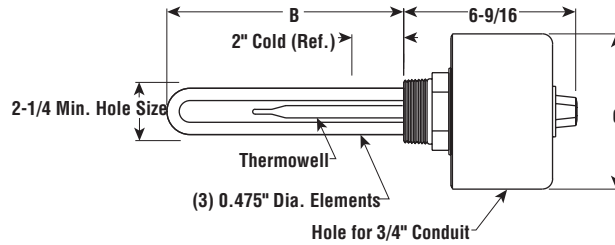

E2 — Dimensions (Inches)

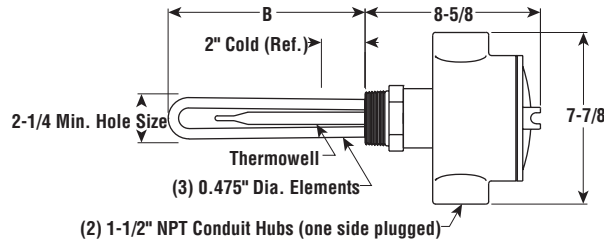

Specifications and Ordering Information

							T2 — Temperature (60 - 250°F)			T1 — Temperature (0 - 100°F)		
kW	Volts	Phase	W/In ²	No. Elem.	DIM B (In.)	Wt. (Lbs.)	Model	Stock	PCN	Model	Stock	PCN
E1 General Purpose¹												
1	240	3	15	3	7-3/4	7	AREMTS-3015T2	NS	091328	AREMTS-3015T1	NS	033734
1	480	3	15	3	7-3/4	7	AREMTS-3015T2	NS	091336	AREMTS-3015T1	NS	033742
2	240	3	15	3	17-3/4	8	AREMTS-3025T2	NS	091344	AREMTS-3025T1	NS	033750
2	480	3	15	3	17-3/4	8	AREMTS-3025T2	NS	091352	AREMTS-3025T1	NS	033769
3	240	3	15	3	24-7/8	9	AREMTS-3035T2	NS	091360	AREMTS-3035T1	NS	033777
3	480	3	15	3	24-7/8	9	AREMTS-3035T2	NS	091379	AREMTS-3035T1	NS	033785
4	240	3	15	3	32-7/16	10	AREMTS-3045T2	NS	091387	AREMTS-3045T1	NS	033793
4	480	3	15	3	32-7/16	10	AREMTS-3045T2	NS	091395	AREMTS-3045T1	NS	033806
5	240	3	15	3	40-3/8	11	AREMTS-3055T2	NS	091408	AREMTS-3055T1	NS	033814
5	480	3	15	3	40-3/8	11	AREMTS-3055T2	NS	091416	AREMTS-3055T1	NS	033822
6	240	3	15	3	47-7/8	12	AREMTS-3065T2	NS	091424	AREMTS-3065T1	NS	033830
6	480	3	15	3	47-7/8	12	AREMTS-3065T2	NS	091432	AREMTS-3065T1	NS	033849
E2 Moisture Resistant/Explosion Resistant²												
1	240	3	15	3	7-3/4	12	AREMTS-3015E2T2	NS	033857	AREMTS-3015E2T1	NS	033970
1	480	3	15	3	7-3/4	12	AREMTS-3015E2T2	NS	033865	AREMTS-3015E2T1	NS	033988
2	240	3	15	3	17-3/4	13	AREMTS-3025E2T2	NS	033873	AREMTS-3025E2T1	NS	033996
2	480	3	15	3	17-3/4	13	AREMTS-3025E2T2	NS	033881	AREMTS-3025E2T1	NS	034008
3	240	3	15	3	24-7/8	14	AREMTS-3035E2T2	NS	033890	AREMTS-3035E2T1	NS	034016
3	480	3	15	3	24-7/8	14	AREMTS-3035E2T2	NS	033902	AREMTS-3035E2T1	NS	034024
4	240	3	15	3	32-7/16	15	AREMTS-3045E2T2	NS	033910	AREMTS-3045E2T1	NS	034032
4	480	3	15	3	32-7/16	15	AREMTS-3045E2T2	NS	033929	AREMTS-3045E2T1	NS	034040
5	240	3	15	3	40-3/8	16	AREMTS-3055E2T2	NS	033937	AREMTS-3055E2T1	NS	034059
5	480	3	15	3	40-3/8	16	AREMTS-3055E2T2	NS	033945	AREMTS-3055E2T1	NS	034067
6	240	3	15	3	47-7/8	17	AREMTS-3065E2T2	NS	033953	AREMTS-3065E2T1	NS	034075
6	480	3	15	3	47-7/8	17	AREMTS-3065E2T2	NS	033961	AREMTS-3065E2T1	NS	034083

Stock Status: S = stock NS = non-stock
To Order—Specify model, volts, phase, kW, PCN and quantity.

1. Heaters with General Purpose Enclosures are UL Listed and CSA Certified.
2. Heaters with Moisture Resistant/Explosion Resistant Enclosures are ^cCSA_{US}® Certified.



Same-day shipping on stock item orders received before 4 pm CST. 3-day shipping on assembly-stock items.