


Immersion

ARMTO-3 Light Weight Oil Applications



- 2-1/2" NPT Steel Screw Plug
- Steel Sheath Elements
- 23 - 26 W/In²
- 3 - 9 kW
- Integral Thermostat (DPST)
- 208, 240 and 480 Volt, 1 and 3 Phase
- General Purpose Terminal Enclosure

E1 — Dimensions (Inches)

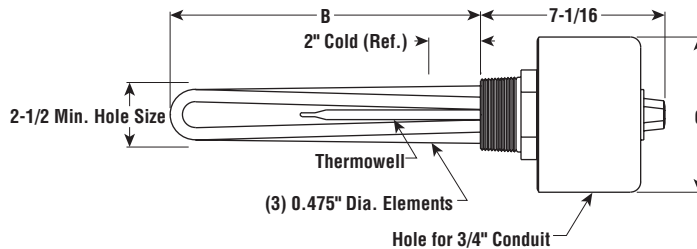

SCREW PLUG

Specifications and Ordering Information

							T3 — Temperature (200 - 550°F)			T2 — Temperature (60 - 250°F)			T1 — Temperature (0 - 100°F)		
kW	Volts	Phase	W/In ²	No. Elem.	DIM B (In.)	Wt. (Lbs.)	Model	Stock	PCN	Model	Stock	PCN	Model	Stock	PCN
E1 General Purpose¹															
3	208	1	24	3	17-3/8	9	ARMTO-3305T3	NS	320012	ARMTO-3305T2	NS	320020	ARMTO-3305T1	NS	320039
3	208	3	24	3	17-3/8	9	ARMTO-3305T3	NS	320071	ARMTO-3305T2	NS	320080	ARMTO-3305T1	NS	320098
3	240	1	24	3	17-3/8	9	ARMTO-3305T3	NS	286731	ARMTO-3305T2	NS	286723	ARMTO-3305T1	NS	286715
3	240	3	24	3	17-3/8	9	ARMTO-3305T3	NS	286782	ARMTO-3305T2	NS	275135	ARMTO-3305T1	NS	286774
3	480	1	24	3	17-3/8	9	ARMTO-3305T3	NS	286846	ARMTO-3305T2	NS	286838	ARMTO-3305T1	NS	286820
3	480	3	24	3	17-3/8	9	ARMTO-3305T3	NS	275098	ARMTO-3305T2	S	275127	ARMTO-3305T1	S	286889
3.75	208	1	26	3	19-1/8	10	ARMTO-3375T3	NS	320135	ARMTO-3375T2	NS	320143	ARMTO-3375T1	NS	320151
3.75	208	3	26	3	19-1/8	10	ARMTO-3375T3	NS	320194	ARMTO-3375T2	NS	320207	ARMTO-3375T1	NS	320215
3.75	240	1	26	3	19-1/8	10	ARMTO-3375T3	NS	286934	ARMTO-3375T2	NS	286926	ARMTO-3375T1	NS	286918
3.75	240	3	26	3	19-1/8	10	ARMTO-3375T3	NS	286985	ARMTO-3375T2	NS	286977	ARMTO-3375T1	NS	275143
3.75	480	1	26	3	19-1/8	10	ARMTO-3375T3	NS	287048	ARMTO-3375T2	NS	287030	ARMTO-3375T1	NS	287021
3.75	480	3	26	3	19-1/8	10	ARMTO-3375T3	NS	275100	ARMTO-3375T2	NS	287099	ARMTO-3375T1	NS	287080
4.5	208	1	24	3	24-1/2	11	ARMTO-3455T3	NS	320258	ARMTO-3455T2	NS	320266	ARMTO-3455T1	NS	320274
4.5	208	3	24	3	24-1/2	11	ARMTO-3455T3	NS	320311	ARMTO-3455T2	NS	320320	ARMTO-3455T1	NS	320338
4.5	240	1	24	3	24-1/2	11	ARMTO-3455T3	NS	287144	ARMTO-3455T2	NS	271169	ARMTO-3455T1	NS	287136
4.5	240	3	24	3	24-1/2	11	ARMTO-3455T3	NS	287208	ARMTO-3455T2	NS	287195	ARMTO-3455T1	NS	287187
4.5	480	1	24	3	24-1/2	11	ARMTO-3455T3	NS	287275	ARMTO-3455T2	NS	287267	ARMTO-3455T1	NS	287259
4.5	480	3	24	3	24-1/2	11	ARMTO-3455T3	NS	287312	ARMTO-3455T2	S	275151	ARMTO-3455T1	NS	287304
6	208	1	23	3	32-3/8	12	ARMTO-3605T3	NS	320370	ARMTO-3605T2	NS	320389	ARMTO-3605T1	NS	320397
6	208	3	23	3	32-3/8	12	ARMTO-3605T3	NS	320434	ARMTO-3605T2	NS	320442	ARMTO-3605T1	NS	320450
6	240	1	23	3	32-3/8	12	ARMTO-3605T3	NS	287363	ARMTO-3605T2	NS	271177	ARMTO-3605T1	NS	287355
6	240	3	23	3	32-3/8	12	ARMTO-3605T3	NS	287427	ARMTO-3605T2	NS	287419	ARMTO-3605T1	NS	287400
6	480	1	23	3	32-3/8	12	ARMTO-3605T3	NS	287486	ARMTO-3605T2	NS	287478	ARMTO-3605T1	NS	287460
6	480	3	23	3	32-3/8	12	ARMTO-3605T3	NS	275119	ARMTO-3605T2	NS	275160	ARMTO-3605T1	NS	287523
7.5	208	1	23	3	39-7/8	13	ARMTO-3755T3	NS	320493	ARMTO-3755T2	NS	320506	ARMTO-3755T1	NS	320514
7.5	208	3	23	3	39-7/8	13	ARMTO-3755T3	NS	320557	ARMTO-3755T2	NS	320565	ARMTO-3755T1	NS	320573
7.5	240	1	23	3	39-7/8	13	ARMTO-3755T3	NS	287582	ARMTO-3755T2	NS	287574	ARMTO-3755T1	NS	287566
7.5	240	3	23	3	39-7/8	13	ARMTO-3755T3	NS	287646	ARMTO-3755T2	NS	287638	ARMTO-3755T1	NS	287620
7.5	480	1	23	3	39-7/8	13	ARMTO-3755T3	NS	287700	ARMTO-3755T2	NS	287697	ARMTO-3755T1	NS	287689
7.5	480	3	23	3	39-7/8	13	ARMTO-3755T3	NS	287750	ARMTO-3755T2	NS	275178	ARMTO-3755T1	NS	287742
9	208	1	23	3	47-3/8	14	ARMTO-3905T3	NS	320610	ARMTO-3905T2	NS	320629	ARMTO-3905T1	NS	320637
9	208	3	23	3	47-3/8	14	ARMTO-3905T3	NS	320670	ARMTO-3905T2	NS	320688	ARMTO-3905T1	NS	320696
9	240	1	23	3	47-3/8	14	ARMTO-3905T3	NS	287806	ARMTO-3905T2	NS	287793	ARMTO-3905T1	NS	287785
9	240	3	23	3	47-3/8	14	ARMTO-3905T3	NS	287865	ARMTO-3905T2	NS	287857	ARMTO-3905T1	NS	287849
9	480	1	23	3	47-3/8	14	ARMTO-3905T3	NS	287928	ARMTO-3905T2	NS	287910	ARMTO-3905T1	NS	287902
9	480	3	23	3	47-3/8	14	ARMTO-3905T3	NS	287988	ARMTO-3905T2	S	287970	ARMTO-3905T1	NS	287961

Stock Status: S = stock NS = non-stock
To Order—Specify model, volts, phase, kW, PCN and quantity.

1. Heaters are UL Listed with T1 or T2 Temperature and CSA Certified with T1, T2 or T3 Temperature.

FASTShip

Same-day shipping on stock item orders received before 4 pm CST. 3-day shipping on assembly-stock items.