


ARMTO-3 Light Weight Oil Applications (cont'd.)

- 2-1/2" NPT Steel Screw Plug
- Steel Sheath Elements
- 23 - 26 W/In²
- 3 - 9 kW
- Integral Thermostat (DPST)
- 208, 240 and 480 Volt,
1 and 3 Phase
- Moisture Resistant/Explosion
Resistant Terminal Enclosure



E2 — Dimensions (Inches)

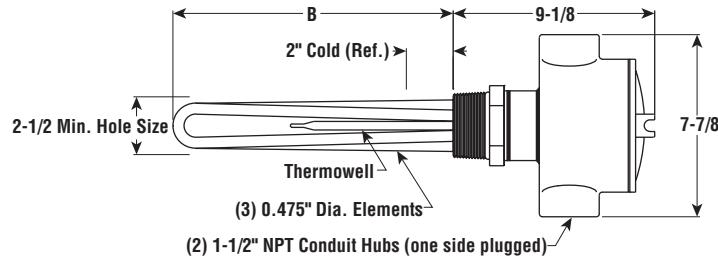

FASTShip

Same-day shipping on stock item orders received before 4 pm CST.
3-day shipping on assembly-stock items.

Specifications and Ordering Information

							T3 — Temperature (200 - 550°F)			T2 — Temperature (60 - 250°F)			T1 — Temperature (0 - 100°F)		
KW	Volts	Phase	W/In ²	No. Elem.	DIM B (In.)	Wt. (Lbs.)	Model	Stock	PCN	Model	Stock	PCN	Model	Stock	PCN
E2 Moisture Resistant/Explosion Resistant															
3	208	1	24	3	17-3/8	14	ARMTO-3305E2T3	NS	320047	ARMTO-3305E2T2	NS	320055	ARMTO-3305E2T1	NS	320063
3	208	3	24	3	17-3/8	14	ARMTO-3305E2T3	NS	320100	ARMTO-3305E2T2	NS	320119	ARMTO-3305E2T1	NS	320127
3	240	1	24	3	17-3/8	14	ARMTO-3305E2T3	NS	286766	ARMTO-3305E2T2	NS	286758	ARMTO-3305E2T1	NS	286740
3	240	3	24	3	17-3/8	14	ARMTO-3305E2T3	NS	286811	ARMTO-3305E2T2	NS	286803	ARMTO-3305E2T1	NS	286790
3	480	1	24	3	17-3/8	14	ARMTO-3305E2T3	NS	286870	ARMTO-3305E2T2	NS	286862	ARMTO-3305E2T1	NS	286854
3	480	3	24	3	17-3/8	14	ARMTO-3305E2T3	NS	286900	ARMTO-3305E2T2	S	275186	ARMTO-3305E2T1	NS	286897
3.75	208	1	26	3	19-1/8	15	ARMTO-3375E2T3	NS	320160	ARMTO-3375E2T2	NS	320178	ARMTO-3375E2T1	NS	320186
3.75	208	3	26	3	19-1/8	15	ARMTO-3375E2T3	NS	320223	ARMTO-3375E2T2	NS	320231	ARMTO-3375E2T1	NS	320240
3.75	240	1	26	3	19-1/8	15	ARMTO-3375E2T3	NS	286969	ARMTO-3375E2T2	NS	286950	ARMTO-3375E2T1	NS	286942
3.75	240	3	26	3	19-1/8	15	ARMTO-3375E2T3	NS	287013	ARMTO-3375E2T2	NS	287005	ARMTO-3375E2T1	NS	286993
3.75	480	1	26	3	19-1/8	15	ARMTO-3375E2T3	NS	287072	ARMTO-3375E2T2	NS	287064	ARMTO-3375E2T1	NS	287056
3.75	480	3	26	3	19-1/8	15	ARMTO-3375E2T3	NS	287128	ARMTO-3375E2T2	NS	287110	ARMTO-3375E2T1	NS	287101
4.5	208	1	24	3	24-1/2	16	ARMTO-3455E2T3	NS	320282	ARMTO-3455E2T2	NS	320290	ARMTO-3455E2T1	NS	320303
4.5	208	3	24	3	24-1/2	16	ARMTO-3455E2T3	NS	320346	ARMTO-3455E2T2	NS	320354	ARMTO-3455E2T1	NS	320362
4.5	240	1	24	3	24-1/2	16	ARMTO-3455E2T3	NS	287179	ARMTO-3455E2T2	NS	287160	ARMTO-3455E2T1	NS	287152
4.5	240	3	24	3	24-1/2	16	ARMTO-3455E2T3	NS	287240	ARMTO-3455E2T2	NS	287232	ARMTO-3455E2T1	NS	287216
4.5	480	1	24	3	24-1/2	16	ARMTO-3455E2T3	NS	287291	ARMTO-3455E2T2	NS	275194	ARMTO-3455E2T1	NS	287283
4.5	480	3	24	3	24-1/2	16	ARMTO-3455E2T3	NS	287347	ARMTO-3455E2T2	S	287339	ARMTO-3455E2T1	S	287320
6	208	1	23	3	32-3/8	17	ARMTO-3605E2T3	NS	320400	ARMTO-3605E2T2	NS	320418	ARMTO-3605E2T1	NS	320426
6	208	3	23	3	32-3/8	17	ARMTO-3605E2T3	NS	320469	ARMTO-3605E2T2	NS	320477	ARMTO-3605E2T1	NS	320485
6	240	1	23	3	32-3/8	17	ARMTO-3605E2T3	NS	287398	ARMTO-3605E2T2	NS	287380	ARMTO-3605E2T1	NS	287371
6	240	3	23	3	32-3/8	17	ARMTO-3605E2T3	NS	287451	ARMTO-3605E2T2	NS	287443	ARMTO-3605E2T1	NS	287435
6	480	1	23	3	32-3/8	17	ARMTO-3605E2T3	NS	287515	ARMTO-3605E2T2	NS	287507	ARMTO-3605E2T1	NS	287494
6	480	3	23	3	32-3/8	17	ARMTO-3605E2T3	NS	287558	ARMTO-3605E2T2	S	287540	ARMTO-3605E2T1	NS	287531
7.5	208	1	23	3	39-7/8	18	ARMTO-3755E2T3	NS	320522	ARMTO-3755E2T2	NS	320530	ARMTO-3755E2T1	NS	320549
7.5	208	3	23	3	39-7/8	18	ARMTO-3755E2T3	NS	320581	ARMTO-3755E2T2	NS	320590	ARMTO-3755E2T1	NS	320602
7.5	240	1	23	3	39-7/8	18	ARMTO-3755E2T3	NS	287611	ARMTO-3755E2T2	NS	287603	ARMTO-3755E2T1	NS	287590
7.5	240	3	23	3	39-7/8	18	ARMTO-3755E2T3	NS	287670	ARMTO-3755E2T2	NS	287662	ARMTO-3755E2T1	NS	287654
7.5	480	1	23	3	39-7/8	18	ARMTO-3755E2T3	NS	287734	ARMTO-3755E2T2	NS	287726	ARMTO-3755E2T1	NS	287718
7.5	480	3	23	3	39-7/8	18	ARMTO-3755E2T3	NS	275207	ARMTO-3755E2T2	NS	287777	ARMTO-3755E2T1	NS	287769
9	208	1	23	3	47-3/8	19	ARMTO-3905E2T3	NS	320645	ARMTO-3905E2T2	NS	320653	ARMTO-3905E2T1	NS	320661
9	208	3	23	3	47-3/8	19	ARMTO-3905E2T3	NS	320709	ARMTO-3905E2T2	NS	320717	ARMTO-3905E2T1	NS	320725
9	240	1	23	3	47-3/8	19	ARMTO-3905E2T3	NS	287830	ARMTO-3905E2T2	NS	287822	ARMTO-3905E2T1	NS	287814
9	240	3	23	3	47-3/8	19	ARMTO-3905E2T3	NS	287890	ARMTO-3905E2T2	NS	287881	ARMTO-3905E2T1	NS	287873
9	480	1	23	3	47-3/8	19	ARMTO-3905E2T3	NS	287953	ARMTO-3905E2T2	NS	287945	ARMTO-3905E2T1	NS	287937
9	480	3	23	3	47-3/8	19	ARMTO-3905E2T3	NS	288016	ARMTO-3905E2T2	S	288008	ARMTO-3905E2T1	NS	287996

Stock Status: S = stock NS = non-stock
To Order—Specify model, volts, phase, kW, PCN and quantity.