

ARMT-2


Clean Water Applications

- 2" NPT Brass Screw Plug
- Copper Sheath Elements
- High Watt Density (46 - 53 W/In²)
- 1.5 - 15 kW
- Integral Thermostat (DPST)
- 120, 208, 240 and 480 Volt, Single Phase
- General Purpose Terminal Enclosure



SCREW PLUG

E1 — Dimensions (Inches)

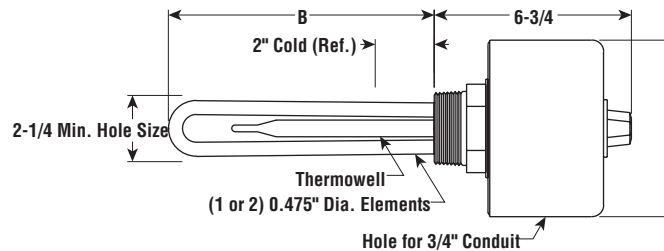

FASTShip™

Same-day shipping on stock item orders received before 4 pm CST. 3-day shipping on assembly-stock items.

Specifications and Ordering Information

							T2 — Temperature (60 - 250°F)			T1 — Temperature (0 - 100°F)		
kW	Volts	Phase	W/In ²	No. Elem.	DIM B (In.)	Wt. (Lbs.)	Model	Stock	PCN	Model	Stock	PCN
E1 General Purpose												
1.5	120	1	48	1	12	5	ARMT-2155T2	NS	270035	ARMT-2155T1	NS	284760
1.5	208	1	48	1	12	5	ARMT-2155T2	NS	323264	ARMT-2155T1	NS	323272
1.5	240	1	48	1	12	5	ARMT-2155T2	S	270043	ARMT-2155T1	NS	284795
2	120	1	51	2	8	5	ARMT-2205-3T2	NS	270060	ARMT-2205-3T1	NS	284824
2	208	1	51	2	8	5	ARMT-2205-3T2	NS	323301	ARMT-2205-3T1	NS	323310
2	240	1	51	2	8	5	ARMT-2205-3T2	NS	270078	ARMT-2205-3T1	NS	284840
2	480	1	51	2	8	5	ARMT-2205-3T2	NS	284883	ARMT-2205-3T1	NS	284875
2.5	208	1	48	2	9-1/2	6	ARMT-2255T2	NS	323344	ARMT-2255T1	NS	323352
2.5	240	1	48	2	9-1/2	6	ARMT-2255T2	NS	270107	ARMT-2255T1	NS	284912
2.5	480	1	48	2	9-1/2	6	ARMT-2255T2	NS	284955	ARMT-2255T1	NS	284947
3	120	1	48	2	12	6	ARMT-2305T2	NS	270123	ARMT-2305T1	NS	284980
3	208	1	48	2	12	6	ARMT-2305T2	NS	323387	ARMT-2305T1	NS	323395
3	240	1	48	2	12	6	ARMT-2305T2	S	270131	ARMT-2305T1	NS	285000
3	480	1	48	2	12	6	ARMT-2305T2	NS	285034	ARMT-2305T1	NS	285026
4	208	1	48	2	18	7	ARMT-2405T2	NS	323424	ARMT-2405T1	NS	323432
4	240	1	48	2	18	7	ARMT-2405T2	S	270166	ARMT-2405T1	NS	285050
4	480	1	48	2	18	7	ARMT-2405T2	NS	285093	ARMT-2405T1	NS	285085
5	208	1	53	2	19-13/16	8	ARMT-2505T2	NS	323467	ARMT-2505T1	NS	323475
5	240	1	53	2	19-13/16	8	ARMT-2505T2	S	270190	ARMT-2505T1	NS	285122
5	480	1	53	2	19-13/16	8	ARMT-2505T2	S	274757	ARMT-2505T1	NS	285157
6	208	1	47	2	25-1/8	8	ARMT-2605T2	NS	323504	ARMT-2605T1	NS	323512
6	240	1	47	2	25-1/8	8	ARMT-2605T2	NS	270211	ARMT-2605T1	NS	285181
6	480	1	47	2	25-1/8	8	ARMT-2605T2	NS	285229	ARMT-2605T1	NS	285210
7	208	1	49	2	28	9	ARMT-2705T2	NS	323547	ARMT-2705T1	NS	323555
7	240	1	49	2	28	9	ARMT-2705T2	NS	270238	ARMT-2705T1	NS	285253
7	480	1	49	2	28	9	ARMT-2705T2	NS	285296	ARMT-2705T1	NS	285288
10	208	1	46	2	40-1/2	9	ARMT-2105T2	NS	323580	ARMT-2105T1	NS	323598
10	240	1	46	2	40-1/2	9	ARMT-2105T2	NS	270019	ARMT-2105T1	NS	284701
10	480	1	46	2	40-1/2	9	ARMT-2105T2	NS	274765	ARMT-2105T1	NS	284736
12	240	1	46	2	48	10	ARMT-2125T2 ¹	NS	310480	ARMT-2125T1 ¹	NS	310527
12	480	1	46	2	48	10	ARMT-2125T2	NS	310498	ARMT-2125T1	NS	310535
15	240	1	50	2	54	11	ARMT-21505T2 ¹	NS	310560	ARMT-21505T1 ¹	NS	310607
15	480	1	50	2	54	11	ARMT-21505T2	NS	310578	ARMT-21505T1	NS	310615

Stock Status: S = stock NS = non-stock
To Order—Specify model, volts, phase, kW, PCN and quantity.

1. Not UL Listed or CSA Certified (Exceeds 48 Amps).