


MTO-3


Light Weight Oil Applications (cont'd.)

- 2-1/2" NPT Steel Screw Plug
- Steel Sheath Elements
- 23 - 26 W/in²
- 3 - 9 kW
- Without Thermostat
- 120, 208, 240 and 480 Volt, 1 and 3 Phase
- General Purpose, Moisture Resistant/Explosion Resistant Terminal Enclosure or Moisture Resistant


E1 — Dimensions (Inches)

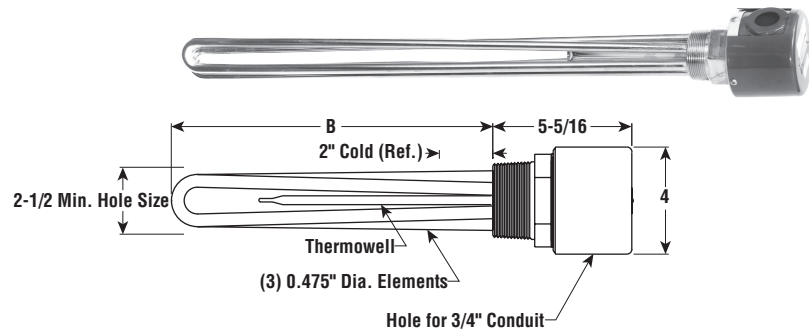

E2 — Dimensions (Inches)

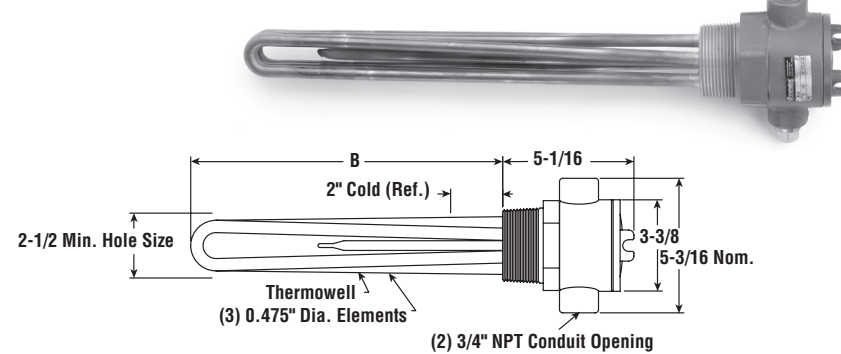

E4TP — Dimensions (Inches)

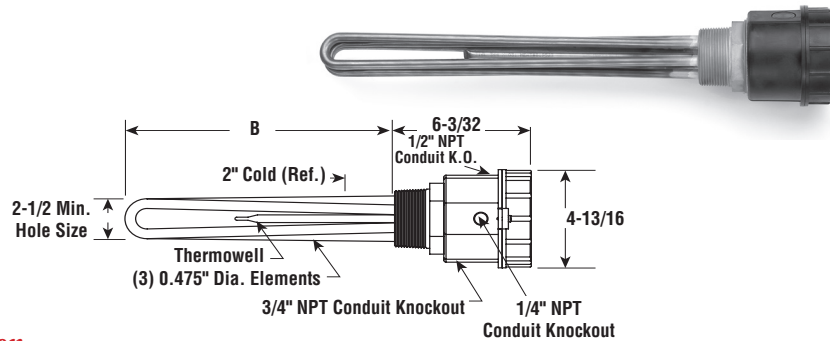

Specifications and Ordering Information

						E1 General Purpose ¹				E2 Moisture Resistant/ Explosion Resistant ²				E4 Moisture Resistant			
kW	Volts	Phase	W/in ²	No. Elem.	DIM B (In.)	Model	Stock	PCN	Wt. (Lbs.)	Model	Stock	PCN	Wt. (Lbs.)	Model	Stock	PCN	Wt. (Lbs.)
7.5	240	1	23	3	39-3/4	MTO-375A	NS	191951	10	MTO-375E2	NS	289262	13	MTO-375E4TP	NS	064792	16
7.5	480	1	23	3	39-3/4	MTO-375A	NS	191960	10	MTO-375E2	NS	289289	13	MTO-375E4TP	NS	064805	16
7.5	240	3	23	3	39-3/4	MTO-375A S	191978	10	10	MTO-375E2	NS	289270	13	MTO-375E4TP	NS	064813	16
7.5	480	3	23	3	39-3/4	MTO-375A S	191986	10	10	MTO-375E2	NS	289297	13	MTO-375E4TP	NS	064821	16
7.5	208	1	23	3	39-3/4	MTO-375A	NS	322165	10	MTO-375E2	NS	322173	13	MTO-375E4TP	NS	064830	16
7.5	208	3	23	3	39-3/4	MTO-375A	NS	322181	10	MTO-375E2	NS	322190	13	MTO-375E4TP	NS	064848	16
9	240	1	23	3	47-1/4	MTO-390A	NS	191994	11	MTO-390E2	NS	289300	14	MTO-390E4TP	NS	064856	17
9	480	1	23	3	47-1/4	MTO-390A	NS	192006	11	MTO-390E2	NS	289326	14	MTO-390E4TP	NS	064864	17
9	240	3	23	3	47-1/4	MTO-390A S	192014	11	11	MTO-390E2	NS	289318	14	MTO-390E4TP	NS	064872	17
9	480	3	23	3	47-1/4	MTO-390A S	192022	11	11	MTO-390E2 S	289334	14	MTO-390E4TP	NS	064880	17	
9	208	1	23	3	47-1/4	MTO-390A	NS	322202	11	MTO-390E2	NS	322210	14	MTO-390E4TP	NS	064899	17
9	208	3	23	3	47-1/4	MTO-390A	NS	322229	11	MTO-390E2	NS	322237	14	MTO-390E4TP	NS	064901	17

Stock Status: S = stock NS = non-stock
To Order—Specify model, volts, phase, kW, PCN and quantity.



1. Heaters with General Purpose Enclosures are UL Recognized and CSA Certified.
2. Heaters with Moisture Resistant/Explosion Resistant Enclosures are _cCSA_{US}® Certified.

Same-day shipping on stock item orders received before 4 pm CST, 3-day shipping on assembly-stock items.