




ARMTO-3 Medium Weight Oil Applications


- 2-1/2" NPT Steel Screw Plug
- Steel Sheath Elements
- 15 W/In²
- 3 - 9 kW
- Integral Thermostat (DPST)
- 240 and 480 Volt, Three Phase
- General Purpose or Moisture Resistant/Explosion Resistant Terminal Enclosure



E1 — Dimensions (Inches)

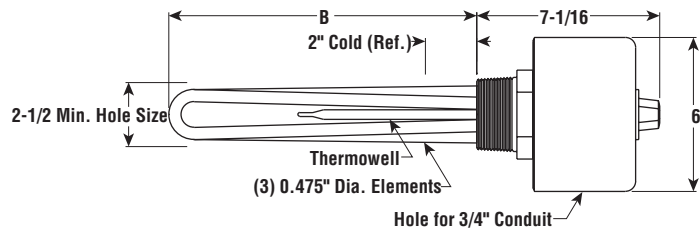

E2 — Dimensions (Inches)

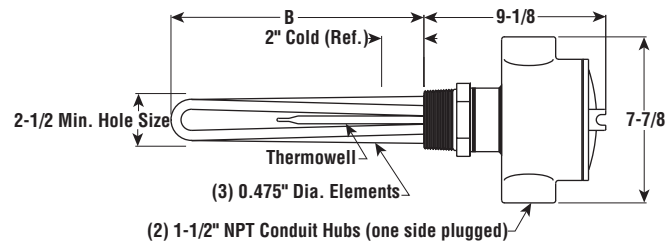

Same-day shipping on stock item
orders received before 4 pm CST.
3-day shipping on assembly-stock items.

Specifications and Ordering Information

							T3 — Temperature (200 - 550°F)			T2 — Temperature (60 - 250°F)			T1 — Temperature (0 - 100°F)		
kW	Volts	Phase	W/In ²	No. Elem.	DIM B (In.)	Wt. (Lbs.)	Model	Stock	PCN	Model	Stock	PCN	Model	Stock	PCN
E1 General Purpose¹															
3	240	3	15	3	24-1/2	11	ARMTO-303T3	NS	324988	ARMTO-303T2	NS	324996	ARMTO-303T1	NS	325008
3	480	3	15	3	24-1/2	11	ARMTO-303T3	NS	325040	ARMTO-303T2	NS	325059	ARMTO-303T1	NS	325067
4	240	3	15	3	32-3/8	12	ARMTO-304T3	NS	325104	ARMTO-304T2	NS	325112	ARMTO-304T1	NS	325120
4	480	3	15	3	32-3/8	12	ARMTO-304T3	NS	325163	ARMTO-304T2	NS	325171	ARMTO-304T1	NS	325180
5	240	3	15	3	39-7/8	13	ARMTO-305T3	NS	325227	ARMTO-305T2	NS	325235	ARMTO-305T1	NS	325243
6	240	3	15	3	47-3/8	14	ARMTO-306T3	NS	325286	ARMTO-306T2	NS	325294	ARMTO-306T1	NS	325307
6	480	3	15	3	47-3/8	14	ARMTO-306T3	NS	325340	ARMTO-306T2	NS	325358	ARMTO-306T1	NS	325366
7.5	240	3	15	3	57	15	ARMTO-307T3	NS	325403	ARMTO-307T2	NS	325411	ARMTO-307T1	NS	325420
9	240	3	15	3	67-3/8	16	ARMTO-309T3	NS	325462	ARMTO-309T2	NS	325470	ARMTO-309T1	NS	325489
E2 Moisture Resistant/Explosion Resistant²															
3	240	3	15	3	24-1/2	16	ARMTO-303E2T3	NS	325016	ARMTO-303E2T2	NS	325024	ARMTO-303E2T1	NS	325032
3	480	3	15	3	24-1/2	16	ARMTO-303E2T3	NS	325075	ARMTO-303E2T2	NS	325083	ARMTO-303E2T1	NS	325091
4	240	3	15	3	32-3/8	17	ARMTO-304E2T3	NS	325139	ARMTO-304E2T2	NS	325147	ARMTO-304E2T1	NS	325155
4	480	3	15	3	32-3/8	17	ARMTO-304E2T3	NS	325198	ARMTO-304E2T2	NS	325200	ARMTO-304E2T1	NS	325219
5	240	3	15	3	39-7/8	18	ARMTO-305E2T3	NS	325251	ARMTO-305E2T2	NS	325260	ARMTO-305E2T1	NS	325278
6	240	3	15	3	47-3/8	19	ARMTO-306E2T3	NS	325315	ARMTO-306E2T2	NS	325323	ARMTO-306E2T1	NS	325331
6	480	3	15	3	47-3/8	19	ARMTO-306E2T3	NS	325374	ARMTO-306E2T2	NS	325382	ARMTO-306E2T1	NS	325390
7.5	240	3	15	3	57	20	ARMTO-307E2T3	NS	325438	ARMTO-307E2T2	NS	325446	ARMTO-307E2T1	NS	325454
9	240	3	15	3	67-3/8	21	ARMTO-309E2T3	NS	325497	ARMTO-309E2T2	NS	325500	ARMTO-309E2T1	NS	325518

Stock Status: S = stock NS = non-stock
To Order—Specify model, volts, phase, kW, PCN and quantity.

1. Heaters with General Purpose Enclosures are UL Listed with T1 or T2 Temperature and CSA Certified with T1, T2 or T3 Temperature.
 2. Heaters with Moisture Resistant/Explosion Resistant Enclosures are ^cCSA_{US}® Certified with T1, T2 or T3 Temperature.