


ARMT-2 Clean Water Applications *(cont'd.)*

- 2" NPT Brass Screw Plug
- Copper Sheath Elements
- High Watt Density (46 - 53 W/in²)
- 1.5 - 15 kW
- Integral Thermostat (DPST)
- 120, 208, 240 and 480 Volt, Single Phase
- Moisture Resistant/Explosion Resistant Terminal Enclosure



E2 — Dimensions (Inches)

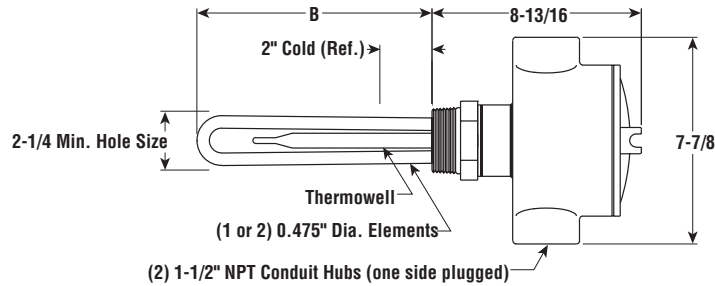

FASTShip

Same-day shipping on stock item orders received before 4 pm CST.
3-day shipping on assembly-stock items.

Specifications and Ordering Information

							T2 — Temperature (60 - 250°F)			T1 — Temperature (0 - 100°F)		
kW	Volts	Phase	W/in ²	No. Elem.	DIM B (In.)	Wt. (Lbs.)	Model	Stock	PCN	Model	Stock	PCN
E2 Moisture Resistant/Explosion Resistant												
1.5	120	1	48	1	12	10	ARMT-2155E2T2	NS	284787	ARMT-2155E2T1	NS	284779
1.5	208	1	48	1	12	10	ARMT-2155E2T2	NS	323280	ARMT-2155E2T1	NS	323299
1.5	240	1	48	1	12	10	ARMT-2155E2T2	NS	284816	ARMT-2155E2T1	NS	284808
2	120	1	51	2	8	10	ARMT-2205-3E2T2	NS	284832	ARMT-2205-3E2T1	NS	274773
2	208	1	51	2	8	10	ARMT-2205-3E2T2	NS	323328	ARMT-2205-3E2T1	NS	323336
2	240	1	51	2	8	10	ARMT-2205-3E2T2	NS	284867	ARMT-2205-3E2T1	NS	284859
2	480	1	51	2	8	10	ARMT-2205-3E2T2	NS	284904	ARMT-2205-3E2T1	NS	284891
2.5	208	1	48	2	9-1/2	12	ARMT-2255E2T2	NS	323360	ARMT-2255E2T1	NS	323379
2.5	240	1	48	2	9-1/2	12	ARMT-2255E2T2	NS	284939	ARMT-2255E2T1	NS	284920
2.5	480	1	48	2	9-1/2	12	ARMT-2255E2T2	NS	284971	ARMT-2255E2T1	NS	284963
3	120	1	48	2	12	12	ARMT-2305E2T2	NS	285018	ARMT-2305E2T1	NS	284998
3	208	1	48	2	12	12	ARMT-2305E2T2	NS	323408	ARMT-2305E2T1	NS	323416
3	240	1	48	2	12	12	ARMT-2305E2T2	NS	274781	ARMT-2305E2T1	NS	274802
3	480	1	48	2	12	12	ARMT-2305E2T2	NS	274790	ARMT-2305E2T1	NS	285042
4	208	1	48	2	18	13	ARMT-2405E2T2	NS	323440	ARMT-2405E2T1	NS	323459
4	240	1	48	2	18	13	ARMT-2405E2T2	NS	285077	ARMT-2405E2T1	NS	285069
4	480	1	48	2	18	13	ARMT-2405E2T2	NS	285114	ARMT-2405E2T1	NS	285106
5	208	1	53	2	19-13/16	14	ARMT-2505E2T2	NS	323483	ARMT-2505E2T1	NS	323491
5	240	1	53	2	19-13/16	14	ARMT-2505E2T2	NS	285149	ARMT-2505E2T1	NS	285130
5	480	1	53	2	19-13/16	14	ARMT-2505E2T2	NS	285173	ARMT-2505E2T1	NS	285165
6	208	1	47	2	25-1/8	14	ARMT-2605E2T2	NS	323520	ARMT-2605E2T1	NS	323539
6	240	1	47	2	25-1/8	14	ARMT-2605E2T2	NS	285202	ARMT-2605E2T1	NS	285190
6	480	1	47	2	25-1/8	14	ARMT-2605E2T2	NS	285245	ARMT-2605E2T1	NS	285237
7	208	1	49	2	28	15	ARMT-2705E2T2	NS	323563	ARMT-2705E2T1	NS	323571
7	240	1	49	2	28	15	ARMT-2705E2T2	NS	285270	ARMT-2705E2T1	NS	285261
7	480	1	49	2	28	15	ARMT-2705E2T2	NS	285309	ARMT-2705E2T1	NS	285317
10	208	1	46	2	40-1/2	16	ARMT-2105E2T2	NS	323600	ARMT-2105E2T1	NS	323619
10	240	1	46	2	40-1/2	16	ARMT-2105E2T2	NS	284728	ARMT-2105E2T1	NS	284710
10	480	1	46	2	40-1/2	16	ARMT-2105E2T2	NS	284752	ARMT-2105E2T1	NS	284744
12	240	1	46	2	48	17	ARMT-2125E2T2 ¹	NS	310500	ARMT-2125E2T1 ¹	NS	310543
12	480	1	46	2	48	17	ARMT-2125E2T2	NS	310519	ARMT-2125E2T1	NS	310551
15	240	1	50	2	54	18	ARMT-21505E2T2 ¹	NS	310586	ARMT-21505E2T1 ¹	NS	310623
15	480	1	50	2	54	18	ARMT-21505E2T2	NS	310594	ARMT-21505E2T1	NS	310631

Stock Status: S = stock NS = non-stock
To Order—Specify model, volts, phase, kW, PCN and quantity.

1. Not ^CCSA_{US}® Certified (Exceeds 48 Amps).