


TM-1 & TMO-1 Small Tank Applications



- 1" NPT Brass or Steel Screw Plug
- Copper or Steel Sheath Element
- 20 - 86 W/in²
- 350 - 1,500 Watts
- 120 and 240 Volt, Single Phase
- Integral Plug and Receptacle

Dimensions (Inches)

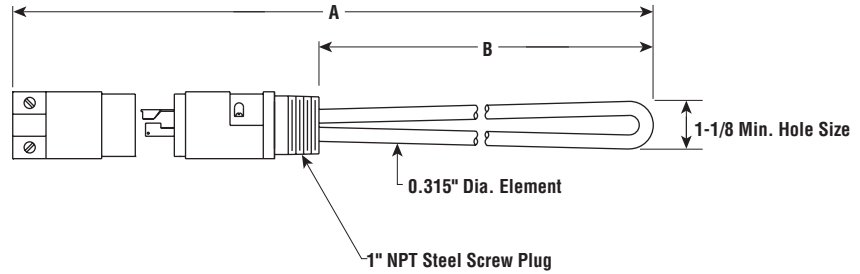

Applications

- Water Heating (type TM-1)
- Light Weight Oil Heating (type TMO-1)

Specifications and Ordering Information

Watts	Volts	Phase	W/in ²	Dimensions (In.)		Model	Stock	PCN	Wt. (Oz.)
				A	B				
TM-1 — Copper Sheath Element for Water Heating — Brass Screw Plug									
350	120	1	46	8-5/8	4-3/8	TM-1036G	S	138819	14
500	120	1	43	10-3/4	6-1/2	TM-1051G	NS	138827	14
500	240	1	43	10-3/4	6-1/2	TM-1051G	NS	138835	14
750	120	1	64	10-3/4	6-1/2	TM-1076G	NS	138843	16
750	240	1	64	10-3/4	6-1/2	TM-1076G	S	138851	16
1,000	120	1	85	10-3/4	6-1/2	TM-1101G	S	138860	16
1,000	240	1	85	10-3/4	6-1/2	TM-1101G	S	138878	16
1,500	120	1	86	13-5/8	9-3/8	TM-1415G	S	138886	17
1,500	240	1	86	13-5/8	9-3/8	TM-1415G	NS	138894	17
TMO-1 — Steel Sheath Element for Oil Heating — Steel Screw Plug									
350	120	1	20	13-1/16	8-7/8	TMO-1036G	S	138907	16
500	120	1	20	17-3/16	13	TMO-1051G	S	138915	18
500	240	1	20	17-3/16	13	TMO-1051G	NS	138923	18
750	120	1	20	23-1/8	18-7/8	TMO-1076G	NS	138931	20
750	240	1	20	23-1/8	18-7/8	TMO-1076G	NS	138940	20
900	120	1	21	25-5/8	21-3/8	TMO-1091G	S	138958	22
900	240	1	21	25-5/8	21-3/8	TMO-1091G	S	138966	22

Stock Status: S = stock NS = non-stock
To Order—Specify model, volts, phase, watts, PCN and quantity.