

Immersion


TM Clean Water Applications

- 3 - 14" 150 Lb. Carbon Steel Flange
- Copper Sheath Elements
- Copper Thermowell
- 45 W/in²
- 6 - 350 kW
- 240 and 480 Volt, 1 & 3 Phase
- General Purpose, Moisture Resistant or Moisture Resistant/Explosion Resistant Terminal Enclosures



Note — Refer to the dimensional reference page for enclosure and flange details.

Dimensions (Inches)

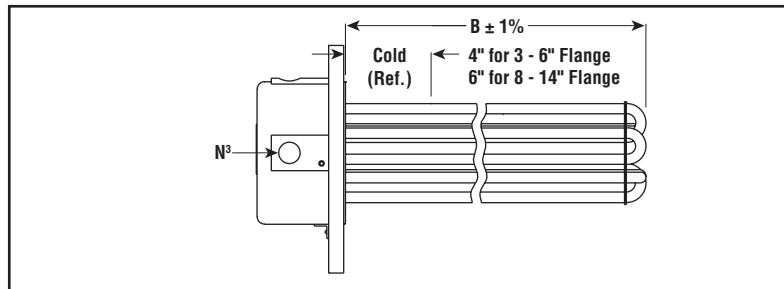

FLANGED

Specifications and Ordering Information

					E1 General Purpose				E2 Moisture Resistant/Explosion Resistant							
kW	Volts	CKT & PhNSe	DIM B (In.)	Wt* (lbs)	Model	Stock	PCN	DIM. N (In.)	Model	Stock	PCN	DIM. N (In.)				
3 Inch - 150 Lb. Steel Flange — 3 Copper Sheath Elements — 45 W/in²																
6	240	1-1	18-1/16	16	TM-03-006P-E1	NS	196066	1	TM-03-006P-E2	NS	180005	3/4				
6	240	1-3	18-1/16	16	TM-03-006P-E1	S	196074	1	TM-03-006P-E2	NS	180013	3/4				
6	480	1-1	18-1/16	16	TM-03-006P-E1	NS	196082	1	TM-03-006P-E2	NS	180021	3/4				
6	480	1-3	18-1/16	16	TM-03-006P-E1	S	196090	1	TM-03-006P-E2	NS	180030	3/4				
9	240	1-1	25-3/16	17	TM-03-009P-E1	NS	196103	1	TM-03-009P-E2	NS	180048	3/4				
9	240	1-3	25-3/16	17	TM-03-009P-E1	S	196111	1	TM-03-009P-E2	NS	180056	3/4				
9	480	1-1	25-3/16	17	TM-03-009P-E1	NS	196120	1	TM-03-009P-E2	NS	180064	3/4				
9	480	1-3	25-3/16	17	TM-03-009P-E1	S	196138	1	TM-03-009P-E2	NS	180072	3/4				
12	240	1-1	33-1/16	18	TM-03-012P-E1	NS	196146	1-1/4	TM-03-012P-E2	NS	180080	1				
12	240	1-3	33-1/16	18	TM-03-012P-E1	S	196154	1	TM-03-012P-E2	NS	180099	3/4				
12	480	1-1	33-1/16	18	TM-03-012P-E1	NS	196162	1	TM-03-012P-E2	NS	180101	3/4				
12	480	1-3	33-1/16	18	TM-03-012P-E1	S	196170	1	TM-03-012P-E2	NS	180110	3/4				
15	240	1-1	40-9/16	20	TM-03-015P-E1	NS	196189	1-1/4	TM-03-015P-E2	NS	180128	1				
15	240	1-3	40-9/16	20	TM-03-015P-E1	NS	196197	1	TM-03-015P-E2	NS	180136	3/4				
15	480	1-1	40-9/16	20	TM-03-015P-E1	NS	196200	1	TM-03-015P-E2	NS	180144	3/4				
15	480	1-3	40-9/16	20	TM-03-015P-E1	S	196218	1	TM-03-015P-E2	NS	180152	3/4				
18	240	1-1	48-1/16	21	TM-03-018P-E1	NS	196226	1-1/4	TM-03-018P-E2	NS	180160	1-1/4				
18	240	1-3	48-1/16	21	TM-03-018P-E1	NS	196234	1	TM-03-018P-E2	NS	180179	3/4				
18	480	1-1	48-1/16	21	TM-03-018P-E1	NS	196242	1	TM-03-018P-E2	NS	180187	3/4				
18	480	1-3	48-1/16	21	TM-03-018P-E1	S	196250	1	TM-03-018P-E2	NS	180195	3/4				
					E1 General Purpose				E2 Moisture Resistant/Explosion Resistant				E4 Moisture Resistant			
kW	Volts	CKT & PhNSe	DIM B (In.)	Wt* (lbs)	Model	Stock	PCN	DIM. N (In.)	Model	Stock	PCN	DIM. N (In.)	Model	Stock	PCN	DIM. N (In.)
5 Inch - 150 Lb. Steel Flange — 6 Copper Sheath Elements — 45 W/in²																
12	240	1-3	18-1/16	30	TM-06-012P-E1	NS	196470	1	TM-06-012P-E2	NS	181147	1-1/2	TM-06-012P-E4	NS	181155	1
12	480	1-3	18-1/16	30	TM-06-012P-E1	NS	196496	1	TM-06-012P-E2	NS	181163	1-1/2	TM-06-012P-E4	NS	181171	1
15	240	1-3	19-3/16	31	TM-06-015P-E1	NS	196517	1	TM-06-015P-E2	NS	181180	1-1/2	TM-06-015P-E4	NS	181198	1
15	480	1-3	19-3/16	31	TM-06-015P-E1	S	196533	1	TM-06-015P-E2	NS	181200	1-1/2	TM-06-015P-E4	NS	181219	1
18	240	1-3	25-3/16	33	TM-06-018P-E1	NS	196550	1	TM-06-018P-E2	NS	181227	1-1/2	TM-06-018P-E4	NS	181235	1
18	480	1-3	25-3/16	33	TM-06-018P-E1	S	196576	1	TM-06-018P-E2	NS	181243	1-1/2	TM-06-018P-E4	NS	181251	1
24	240	2-3	33-1/16	37	TM-06-024P-E1	NS	196592	1	TM-06-024P-E2	NS	181260	1-1/2	TM-06-024P-E4	NS	181278	1
24	480	1-3	33-1/16	37	TM-06-024P-E1	S	196613	1	TM-06-024P-E2	NS	181286	1-1/2	TM-06-024P-E4	NS	181294	1
30	240	2-3	40-9/16	40	TM-06-030P-E1	S	196630	1	TM-06-030P-E3	NS	181307	1-1/2	TM-06-030P-E4	NS	181315	1
30	480	1-3	40-9/16	40	TM-06-030P-E1	S	196656	1	TM-06-030P-E3	NS	181323	1-1/2	TM-06-030P-E4	NS	181331	1