


MT-2 Clean Water Applications


- 2" NPT Brass Screw Plug
- Copper Sheath Elements
- High Watt Density (46 - 53 W/in²)
- 1.5 - 15 kW
- Without Thermostat
- 120, 208, 240 and 480 Volt, Single Phase
- General Purpose, Moisture Resistant/Explosion Resistant Terminal Enclosure or Moisture Resistant

E1 — Dimensions (Inches)

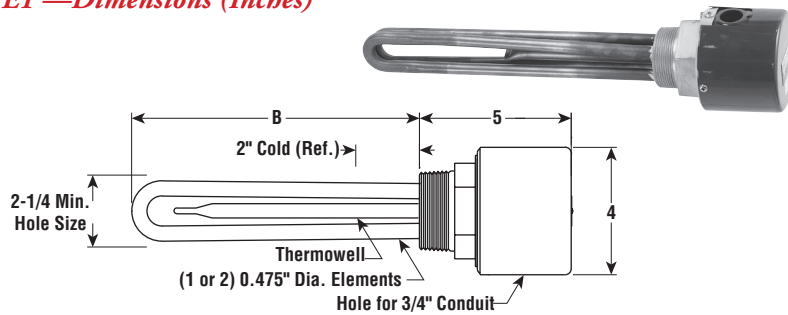


SCREW PLUG

E2 — Dimensions (Inches)

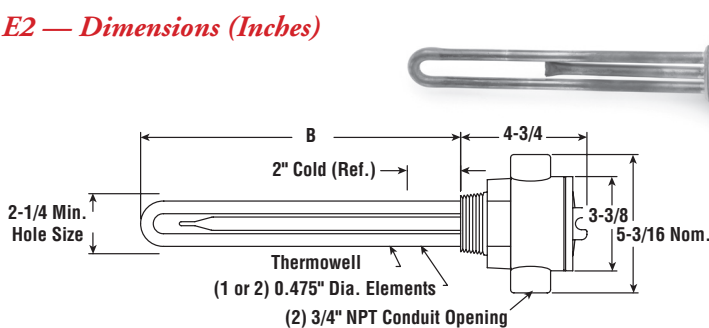

E4TP — Dimensions (Inches)

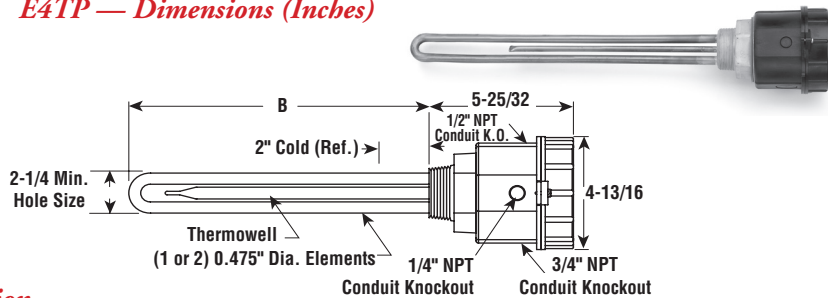

Same-day shipping on stock item
orders received before 4 pm CST.
3-day shipping on assembly-stock items.

Specifications and Ordering Information

						E1 General Purpose ¹				E2 Moisture Resistant/ Explosion Resistant ²				E4 Moisture Resistant			
kW	Volts	Phase	W/in ²	No. Elem.	DIM B (In.)	Model	Stock	PCN	Wt. (Lbs.)	Model	Stock	PCN	Wt. (Lbs.)	Model	Stock	PCN	Wt. (Lbs.)
1.5	120	1	48	1	12	MT-215A	S	139459	3	MT-215E2	NS	288243	6	MT-215E4TP	NS	062164	3
1.5	240	1	48	1	12	MT-215A	NS	139467	3	MT-215E2	NS	288251	6	MT-215E4TP	NS	062172	3
1.5	480	1	48	1	12	MT-215A	S	139475	3	MT-215E2	NS	295005	6	MT-215E4TP	NS	062180	3
1.5	208	1	48	1	12	MT-215A	NS	295275	3	MT-215E2	NS	295283	6	MT-215E4TP	NS	062199	3
2	120	1	48	1	18	MT-220A	S	139483	3	MT-220E2	NS	295013	6	MT-220E4TP	NS	062244	3
2	240	1	48	1	18	MT-220A	S	139491	3	MT-220E2	NS	295048	6	MT-220E4TP	NS	062252	3
2	480	1	48	1	18	MT-220A	S	139504	3	MT-220E2	NS	295056	6	MT-220E4TP	NS	062260	3
2	208	1	48	1	18	MT-220A	NS	295021	3	MT-220E2	NS	295030	6	MT-220E4TP	NS	062279	3
2	120	1	51	2	8	MT-220-3A	NS	139512	3	MT-220-3E2	NS	288260	6	MT-220-3E4TP	NS	062201	3
2	240	1	51	2	8	MT-220-3A	NS	139520	3	MT-220-3E2	NS	288278	6	MT-220-3E4TP	NS	062210	3
2	480	1	51	2	8	MT-220-3A	NS	139539	3	MT-220-3E2	NS	288286	6	MT-220-3E4TP	NS	062228	3
2	208	1	51	2	8	MT-220-3A	NS	295064	3	MT-220-3E2	NS	295072	6	MT-220-3E4TP	NS	062236	3
2.5	120	1	48	2	9-1/2	MT-225A	NS	139547	3	MT-225E2	NS	295080	6	MT-225E4TP	NS	062287	3
2.5	240	1	48	2	9-1/2	MT-225A	S	139555	3	MT-225E2	NS	288294	6	MT-225E4TP	NS	062295	3
2.5	480	1	48	2	9-1/2	MT-225A	NS	139563	3	MT-225E2	NS	288307	6	MT-225E4TP	NS	062308	3
2.5	208	1	48	2	9-1/2	MT-225A	NS	295099	3	MT-225E2	NS	295101	6	MT-225E4TP	NS	062316	3
3	120	1	48	2	12	MT-230A	S	139571	4	MT-230E2	NS	288315	7	MT-230E4TP	NS	062324	4
3	240	1	48	2	12	MT-230A	S	139580	4	MT-230E2	S	288323	7	MT-230E4TP	NS	062332	4
3	480	1	48	2	12	MT-230A	NS	139598	4	MT-230E2	NS	288331	7	MT-230E4TP	NS	062340	4
3	208	1	48	2	12	MT-230A	NS	295110	4	MT-230E2	NS	295128	7	MT-230E4TP	NS	062359	4
4	120	1	48	2	18	MT-240A	NS	139600	4	—	—	—	—	—	—	—	4
4	240	1	48	2	18	MT-240A	NS	139619	4	MT-240E2	NS	288340	7	MT-240E4TP	NS	062375	4
4	480	1	48	2	18	MT-240A	S	139627	4	MT-240E2	S	288358	7	MT-240E4TP	NS	062383	4
4	208	1	48	2	18	MT-240A	NS	295136	4	MT-240E2	NS	295144	7	MT-240E4TP	NS	062391	4
5	120	1	53	2	19-13/16	MT-250A	NS	139635	5	—	—	—	—	—	—	—	5
5	240	1	53	2	19-13/16	MT-250A	S	139643	5	MT-250E2	NS	288366	8	MT-250E4TP	NS	062412	5
5	480	1	53	2	19-13/16	MT-250A	S	139651	5	MT-250E2	S	288374	8	MT-250E4TP	NS	062420	5
5	208	1	53	2	19-13/16	MT-250A	NS	295152	5	MT-250E2	NS	295160	8	MT-250E4TP	NS	062439	5