


# Immersion


## TMI Solution Water Applications

- 3 - 8" 150 Lb. Carbon Steel Flange
- INCOLOY® Sheath Elements
- INCOLOY® Thermowell
- 45 W/in<sup>2</sup>
- 6 - 200 kW
- 240 and 480 Volt, 1 & 3 Phase
- General Purpose, Moisture Resistant or Moisture Resistant/Explosion Resistant Terminal Enclosures

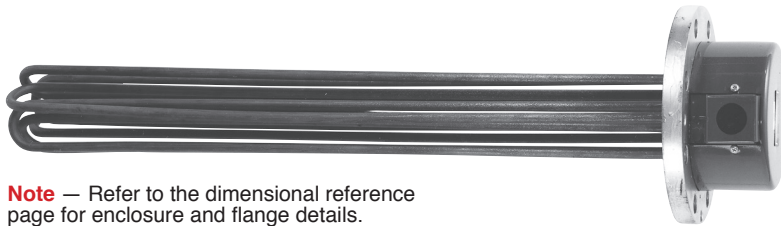

**Note** — Refer to the dimensional reference page for enclosure and flange details.

### Dimensions (Inches)

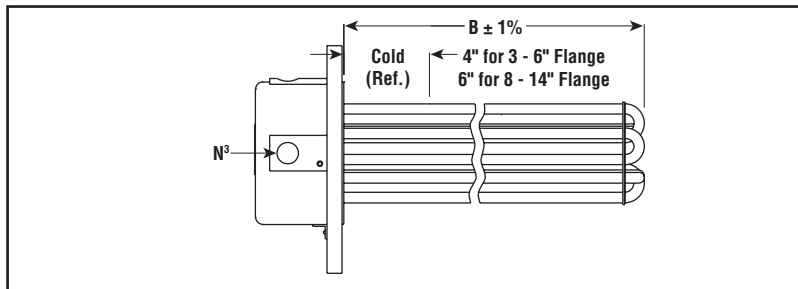

FLANGED

**FASTShip**

Same-day shipping on stock item orders received before 4 pm CST. 3-day shipping on assembly-stock items.

### Specifications and Ordering Information

kW	Volts	CKT & Phase	DIM B (In.)	Wt.* (Lbs.)	E1 General Purpose				E2 Moisture Resistant/Explosion Resistant			
					Model	Stock	PCN	DIM N (In.)	Model	Stock	PCN	DIM N (In.)
<b>3 Inch - 150 Lb. Steel Flange — 3 INCOLOY® Sheath Elements — 45 W/in<sup>2</sup></b>												
6	240	1-1	18-1/16	16	TMI-03-006P-E1	NS	233550	1	TMI-03-006P-E2	NS	233752	3/4
6	240	1-3	18-1/16	16	TMI-03-006P-E1	NS	233568	1	TMI-03-006P-E2	NS	233760	3/4
6	480	1-1	18-1/16	16	TMI-03-006P-E1	NS	233576	1	TMI-03-006P-E2	NS	233779	3/4
6	480	1-3	18-1/16	16	TMI-03-006P-E1	NS	233584	1	TMI-03-006P-E2	NS	233787	3/4
9	240	1-1	25-3/16	17	TMI-03-009P-E1	NS	233592	1	TMI-03-009P-E2	NS	233795	3/4
9	240	1-3	25-3/16	17	TMI-03-009P-E1	NS	233605	1	TMI-03-009P-E2	NS	233808	3/4
9	480	1-1	25-3/16	17	TMI-03-009P-E1	NS	233613	1	TMI-03-009P-E2	NS	233818	3/4
9	480	1-3	25-3/16	17	TMI-03-009P-E1	NS	233621	1	TMI-03-009P-E2	NS	233824	3/4
12	240	1-1	33-1/16	18	TMI-03-012P-E1	NS	233630	1-1/4	TMI-03-012P-E2	NS	233832	1
12	240	1-3	33-1/16	18	TMI-03-012P-E1	NS	233648	1	TMI-03-012P-E2	NS	233840	3/4
12	480	1-1	33-1/16	18	TMI-03-012P-E1	NS	233656	1	TMI-03-012P-E2	NS	233859	3/4
12	480	1-3	33-1/16	18	TMI-03-012P-E1	NS	233664	1	TMI-03-012P-E2	NS	233867	3/4
15	240	1-1	40-9/16	20	TMI-03-015P-E1	NS	233672	1-1/4	TMI-03-015P-E2	NS	233875	1-1/4
15	240	1-3	40-9/16	20	TMI-03-015P-E1	NS	233680	1	TMI-03-015P-E2	NS	233883	3/4
15	480	1-1	40-9/16	20	TMI-03-015P-E1	NS	233699	1	TMI-03-015P-E2	NS	233891	3/4
15	480	1-3	40-9/16	20	TMI-03-015P-E1	NS	233701	1	TMI-03-015P-E2	NS	233904	3/4
18	240	1-1	48-1/16	21	TMI-03-018P-E1	NS	233710	1-1/4	TMI-03-018P-E2	NS	233912	1-1/4
18	240	1-3	48-1/16	21	TMI-03-018P-E1	NS	233728	1	TMI-03-018P-E2	NS	233920	3/4
18	480	1-1	48-1/16	21	TMI-03-018P-E1	NS	233730	1	TMI-03-018P-E2	NS	233939	3/4
18	480	1-3	48-1/16	21	TMI-03-018P-E1	NS	233744	1	TMI-03-018P-E2	NS	233947	3/4