


Immersion

 

TMS Mildly Corrosive Solution Applications

- 3 - 8" 150 Lb. Carbon Steel Flange
- Stainless Steel Sheath Elements
- Stainless Steel Thermowell
- 23 W/in²
- 3 - 50 kW
- 240 and 480 Volt, 1 & 3 Phase
- General Purpose, Moisture Resistant or Moisture Resistant/Explosion Resistant Terminal Enclosures

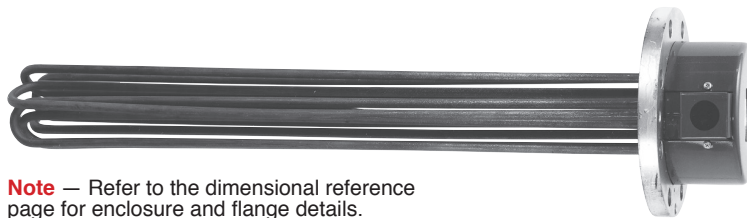

Note — Refer to the dimensional reference page for enclosure and flange details.

Dimensions (Inches)

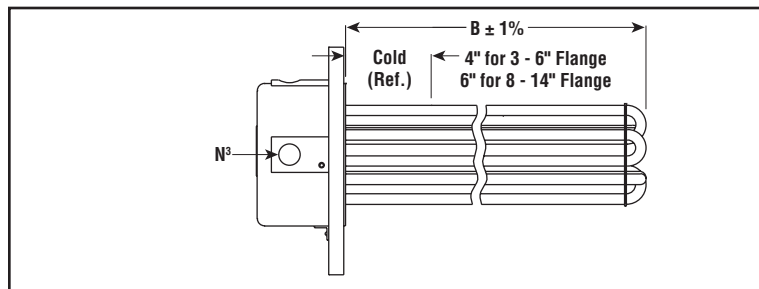

FLANGED

FASTShip

Same-day shipping on stock item orders received before 4 pm CST. 3-day shipping on assembly-stock items.

Specifications and Ordering Information

kW	Volts	CKT & Phase	DIM B (In.)	Wt.* (Lbs.)	E1 General Purpose				E2 Moisture Resistant/Explosion Resistant			
					Model	Stock	PCN	DIM N (In.)	Model	Stock	PCN	DIM N (In.)
3 Inch - 150 Lb. Steel Flange — 3 Stainless Steel Sheath Elements — 23 W/in²												
3	240	1-1	18-1/16	16	TMS-03-003P-E1	NS	231095	1	TMS-03-003P-E2	NS	030015	3/4
3	240	1-3	18-1/16	16	TMS-03-003P-E1	NS	231108	1	TMS-03-003P-E2	NS	030023	3/4
3	480	1-1	18-1/16	16	TMS-03-003P-E1	NS	231116	1	TMS-03-003P-E2	NS	030031	3/4
3	480	1-3	18-1/16	16	TMS-03-003P-E1	NS	231124	1	TMS-03-003P-E2	NS	030040	3/4
4.5	240	1-1	25-3/16	17	TMS-03-004P5-E1	NS	231132	1	TMS-03-004P5-E2	NS	030058	3/4
4.5	240	1-3	25-3/16	17	TMS-03-004P5-E1	NS	231140	1	TMS-03-004P5-E2	NS	030066	3/4
4.5	480	1-1	25-3/16	17	TMS-03-004P5-E1	NS	231159	1	TMS-03-004P5-E2	NS	030074	3/4
4.5	480	1-3	25-3/16	17	TMS-03-004P5-E1	NS	231167	1	TMS-03-004P5-E2	NS	030082	3/4
6	240	1-1	33-1/16	18	TMS-03-006P-E1	NS	231175	1	TMS-03-006P-E2	NS	030090	3/4
6	240	1-3	33-1/16	18	TMS-03-006P-E1	NS	231183	1	TMS-03-006P-E2	NS	030103	3/4
6	480	1-1	33-1/16	18	TMS-03-006P-E1	NS	231191	1	TMS-03-006P-E2	NS	030111	3/4
6	480	1-3	33-1/16	18	TMS-03-006P-E1	NS	231204	1	TMS-03-006P-E2	NS	030120	3/4
7.5	240	1-3	40-9/16	19	TMS-03-007P5-E1	NS	231212	1	TMS-03-007P5-E2	NS	030138	3/4
7.5	480	1-3	40-9/16	19	TMS-03-007P5-E1	NS	231220	1	TMS-03-007P5-E2	NS	030146	3/4
9	480	1-1	48-1/16	21	TMS-03-009P-E1	NS	231239	1	TMS-03-009P-E2	NS	030154	3/4
9	480	1-3	48-1/16	21	TMS-03-009P-E1	NS	231247	1	TMS-03-009P-E2	NS	030162	3/4
9	240	1-3	48-1/16	21	TMS-03-009P-E1	NS	231255	1	TMS-03-009P-E2	NS	030170	3/4