




TMI Corrosive Solution Applications

- 3 - 14" 150 Lb. Carbon Steel Flange
- INCOLOY® Sheath Elements
- INCOLOY® Thermowell
- 20 - 23 W/In²
- 3 - 125 kW
- 240 and 480 Volt, 1 & 3 Phase
- General Purpose, Moisture Resistant or Moisture Resistant/Explosion Resistant Terminal Enclosures

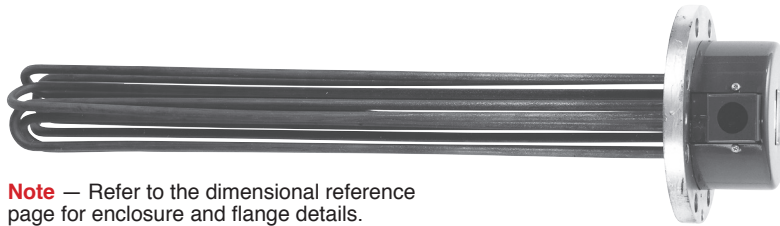

Note — Refer to the dimensional reference page for enclosure and flange details.

 Dimensions (Inches)

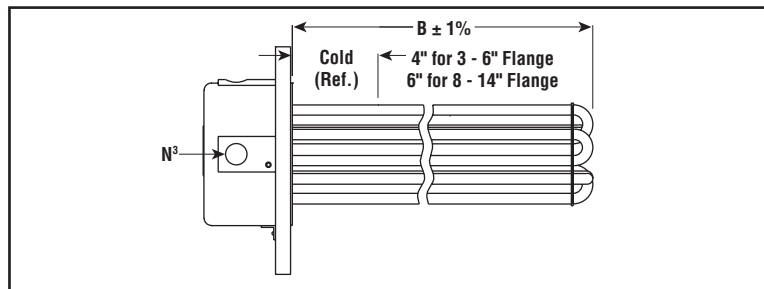

FLANGED

Specifications and Ordering Information

					E1 General Purpose				E2 Moisture Resistant/Explosion Resistant			
kW	Volts	CKT & Phase	DIM B (In.)	Wt.* (Lbs.)	Model	Stock	PCN	DIM N (In.)	Model	Stock	PCN	DIM N (In.)
3 Inch - 150 Lb. Steel Flange — 3 INCOLOY® Sheath Elements — 23 W/In²												
3	240	1-1	18-1/16	16	TMI-03-003P-E1	NS	259397	1	TMI-03-003P-E2	NS	180873	3/4
3	240	1-3	18-1/16	16	TMI-03-003P-E1	NS	256233	1	TMI-03-003P-E2	NS	180881	3/4
3	480	1-1	18-1/16	16	TMI-03-003P-E1	NS	259400	1	TMI-03-003P-E2	NS	180890	3/4
3	480	1-3	18-1/16	16	TMI-03-003P-E1	NS	256241	1	TMI-03-003P-E2	NS	180902	3/4
4.5	240	1-1	25-3/16	17	TMI-03-004P5-E1	NS	259418	1	TMI-03-004P5-E2	NS	180910	3/4
4.5	240	1-3	25-3/16	17	TMI-03-004P5-E1	NS	256250	1	TMI-03-004P5-E2	NS	180929	3/4
4.5	480	1-1	25-3/16	17	TMI-03-004P5-E1	NS	259426	1	TMI-03-004P5-E2	NS	180937	3/4
4.5	480	1-3	25-3/16	17	TMI-03-004P5-E1	NS	256268	1	TMI-03-004P5-E2	NS	180945	3/4
6	240	1-1	33-1/16	18	TMI-03-006P-E1	NS	259434	1	TMI-03-006P-E2	NS	180961	3/4
6	240	1-3	33-1/16	18	TMI-03-006P-E1	NS	256276	1	TMI-03-006P-E2	NS	180953	3/4
6	480	1-1	33-1/16	18	TMI-03-006P-E1	NS	259442	1	TMI-03-006P-E2	NS	180970	3/4
6	480	1-3	33-1/16	18	TMI-03-006P-E1	S	256284	1	TMI-03-006P-E2	NS	180988	3/4
7.5	240	1-3	40-9/16	19	TMI-03-007P5-E1	NS	259477	1	TMI-03-007P5-E2	NS	181104	3/4
7.5	480	1-3	40-9/16	19	TMI-03-007P5-E1	NS	259485	1	TMI-03-007P5-E2	NS	181112	3/4
9	480	1-1	48-1/16	21	TMI-03-009P-E1	NS	259506	1	TMI-03-009P-E2	NS	181059	3/4
9	480	1-3	48-1/16	21	TMI-03-009P-E1	NS	259522	1	TMI-03-009P-E2	NS	181067	3/4
9	240	1-3	48-1/16	21	TMI-03-009P-E1	NS	259514	1	TMI-03-009P-E2	NS	181120	3/4