

TMO

Medium Weight Oil Applications *(cont'd.)*

Specifications and Ordering Information

					E1 General Purpose				E2 Moisture Resistant/Explosion Resistant				E4 Moisture Resistant			
kW	Volts	CKT & Phase	DIM B (In.)	Wt.* (Lbs.)	Model	Stock	PCN	DIM N (In.)	Model	Stock	PCN	DIM N (In.)	Model	Stock	PCN	DIM N (In.)
8 Inch - 150 Lb. Steel Flange — 18 Steel Sheath Elements — 15 W/In²																
20	240	3-3	32-7/8	112	TMO-18-020P-E1	NS	290810	1	TMO-18-020P-E2	NS	290829	3/4	TMO-18-020P-E4	NS	290837	1-1/2
20	480	3-3	32-7/8	112	TMO-18-020P-E1	NS	290845	1	TMO-18-020P-E2	NS	290853	3/4	TMO-18-020P-E4	NS	290861	1-1/2
25	240	3-3	43-11/16	125	TMO-18-025P-E1	NS	290870	1	TMO-18-025P-E2	NS	290888	3/4	TMO-18-025P-E4	NS	290896	1-1/2
25	480	3-3	43-11/16	125	TMO-18-025P-E1	NS	290909	1	TMO-18-025P-E2	NS	290917	3/4	TMO-18-025P-E4	NS	290925	1-1/2
30	240	3-3	51-7/8	130	TMO-18-030P-E1	NS	290933	1	TMO-18-030P-E2	NS	290941	3/4	TMO-18-030P-E4	NS	290950	1-1/2
30	480	3-3	51-7/8	130	TMO-18-030P-E1	NS	290968	1	TMO-18-030P-E2	NS	290976	3/4	TMO-18-030P-E4	NS	290984	1-1/2
35	240	3-3	61-3/8	135	TMO-18-035P-E1	NS	290992	1	TMO-18-035P-E2	NS	291004	3/4	TMO-18-035P-E4	NS	291012	1-1/2
35	480	3-3	61-3/8	135	TMO-18-035P-E1	NS	291020	1	TMO-18-035P-E2	NS	291039	3/4	TMO-18-035P-E4	NS	291047	1-1/2
40	240	3-3	69-7/8	135	TMO-18-040P-E1	NS	291055	1	TMO-18-040P-E2	NS	291063	3/4	TMO-18-040P-E4	NS	291071	1-1/2
40	480	3-3	69-7/8	135	TMO-18-040P-E1	NS	291080	1	TMO-18-040P-E2	NS	291098	3/4	TMO-18-040P-E4	NS	291100	1-1/2
45	240	3-3	78-7/8	147	TMO-18-045P-E1	NS	291119	1	TMO-18-045P-E2	NS	291127	1	TMO-18-045P-E4	NS	291135	1-1/2
45	480	3-3	78-7/8	147	TMO-18-045P-E1	NS	291143	1	TMO-18-045P-E2	NS	291151	3/4	TMO-18-045P-E4	NS	291160	1-1/2

Stock Status: S = stock NS = non-stock
To Order—Specify model, PCN, kW, volts, phase and quantity.
***Weights:**
 A. For Wt. of 3" flange with E2 enclosure add 3 lbs. to Wt. of E1 enclosure heater.
 B. For Wt. of 5 and 6" flange with E4 enclosure add 7 lbs. to Wt. of E1 enclosure heater.
 C. For Wt. of 8" flange with E4 enclosure add 10 lbs. to Wt. of E1 enclosure heater

TMO-3

Medium Weight Oil Applications


- 3" 150 Lb. Carbon Steel Flange
- Steel Sheath Elements
- Steel Thermowell
- Built-in AR Thermostat (60 - 250°F)
 - Single Phase on 480V (contactor required)
 - Three Phase on 240V (no contactor required)
- 15 W/In²
- 3 - 6 kW
- 240 and 480 Volt, Three Phase
- Moisture Resistant/Explosion Resistant Terminal Enclosure

FASTShip

Same-day shipping on stock item orders received before 4 pm CST. 3-day shipping on assembly-stock items.



Dimensions (Inches)

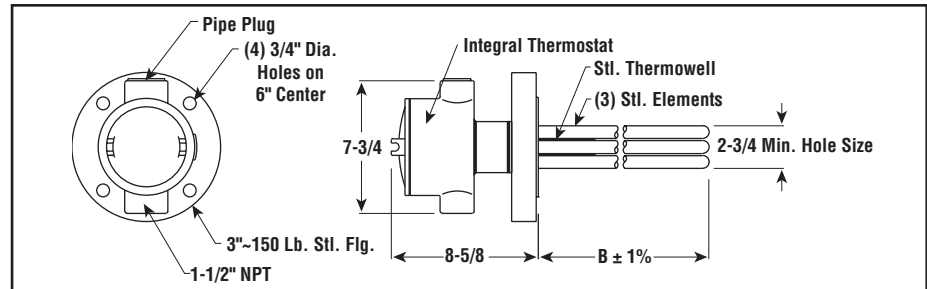

Specifications and Ordering Information

					E2 Moisture Resistant/Explosion Resistant		
kW	Volts	CKT & Phase	DIM B (In.)	Wt. (Lbs.)	Model	Stock	PCN
3 Inch - 150 Lb. Steel Flange — 3 Steel Sheath Elements — 15 W/In²							
3	240	1-3	25-1/4	24	TMO-30315E2T93	NS	326166
3	480	1-3	25-1/4	24	TMO-30315E2T2	NS	326174
4	240	1-3	33-1/16	25	TMO-30415E2T93	NS	326182
4	480	1-3	33-1/16	25	TMO-30415E2T2	NS	326190
6	240	1-3	48-1/16	29	TMO-30615E2T93	NS	326203
6	480	1-3	48-1/16	29	TMO-30615E2T2	NS	326211

Stock Status: S = stock NS = non-stock
To Order—Specify model, PCN, kW, volts, phase and quantity.

Note — Other kW ratings and flange sizes available, contact your Local Chromalox Sales office.