


EMT-3 Clean Water Applications


- 2" NPT Brass Screw Plug
- Copper Sheath Elements
- High Watt Density (61 - 67 W/In²)
- 3 - 12 kW
- Without Thermostat
- 240 and 480 Volt, Three Phase
- General Purpose, Moisture Resistant/Explosion Resistant Terminal Enclosure or Moisture Resistant

E1 — Dimensions (Inches)

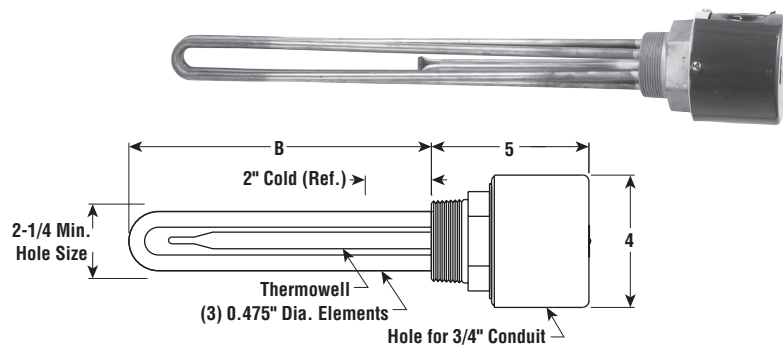


SCREW PLUG

E2 — Dimensions (Inches)

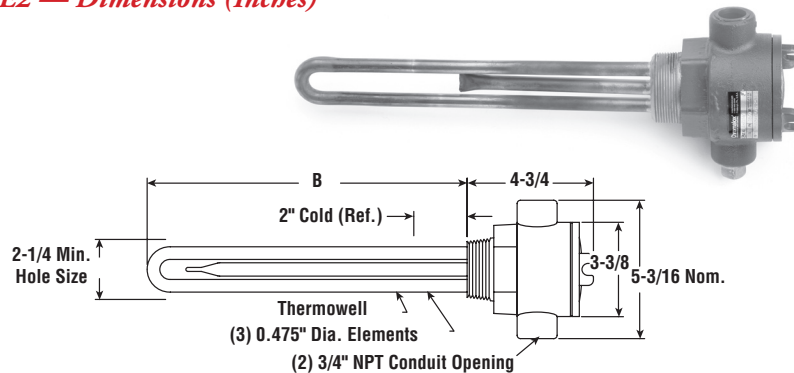

E4TP — Dimensions (Inches)

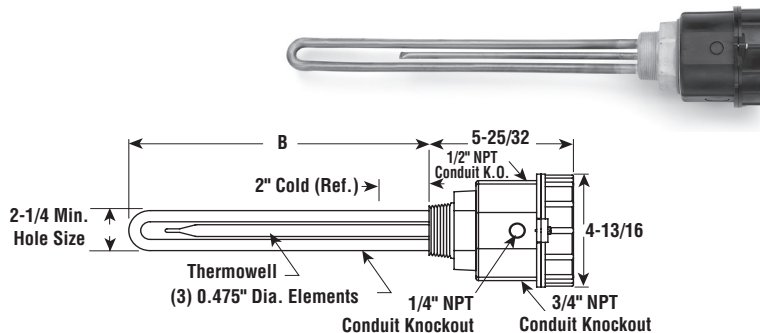

Specifications and Ordering Information

						E1 General Purpose ¹				E2 Moisture Resistant Explosion Resistant ²				E4 Moisture Resistant			
kW	Volts	Phase	W/In ²	No. Elem.	DIM B (In.)	Model	Stock	PCN	Wt. (Lbs.)	Model	Stock	PCN	Wt. (Lbs.)	Model	Stock	PCN	Wt. (Lbs.)
3	240	3	67	3	7	EMT-303	S	326220	5	EMT-303E2	NS	326300	8	EMT-303E4TP	NS	060679	5
3	480	3	67	3	7	EMT-303	S	326238	5	EMT-303E2	NS	326318	8	EMT-303E4TP	NS	060687	5
6	240	3	67	3	12	EMT-306	S	326246	6	EMT-306E2	NS	326326	9	EMT-306E4TP	NS	060695	6
6	480	3	67	3	12	EMT-306	S	326254	6	EMT-306E2	NS	326334	9	EMT-306E4TP	NS	060708	6
9	240	3	65	3	17-1/2	EMT-309	NS	326262	7	EMT-309E2	NS	326342	10	EMT-309E4TP	NS	060716	7
9	480	3	65	3	17-1/2	EMT-309	S	326270	7	EMT-309E2	NS	326350	10	EMT-309E4TP	NS	060724	7
12	240	3	61	3	24	EMT-312	S	326289	8	EMT-312E2	NS	326369	11	EMT-312E4TP	NS	060732	8
12	480	3	61	3	24	EMT-312	S	326297	8	EMT-312E2	NS	326377	11	EMT-312E4TP	NS	060740	8

Stock Status: S = stock NS = non-stock
To Order—Specify model, volts, phase, kW, PCN and quantity.

1. Heaters with General Purpose Enclosures are UL Listed and CSA Certified.
2. Heaters with Moisture Resistant/Explosion Resistant Enclosures are cCSA_{US}® Certified.a

FASTShip

Same-day shipping on stock item orders received before 4 pm CST. 3-day shipping on assembly-stock items.