 



DS41S-400



- UL1449 TYPE 1 LISTED SPD
- MOV Technology
- 40kA Surge Current Rating
- Visual fault indicator and remote contacts
- 10-Year warranty

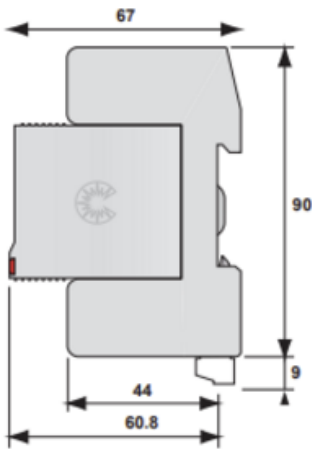

V: High-energy varistor
 Ft: Thermal fuse
 C: Remote signal contact
 t*: Thermal disconnection system
 MI: Disconnection indicator

Electrical Characteristics		
POWER SPD TYPE		UL1449 TYPE 1 LISTED
VOLTS	(V)	277
AC/DC/DC PV/RF		AC
PHASE	(PH)	1
AMPS	(A)	n/a
AMBIENT MIN	(C)	-35
AMBIENT MAX	(C)	+60
MODES		L-G
VPR	(V)	-/-/1500/-
MCOV	(V)	-/-/420/-
IN15 impulses 8/20µs	(kA)	20
SCCR	(kA)	100
IMAX8/20µs	(kA)	40
Iimp10/350µs	(kA)	4
Mechanical Characteristics		
TECHNOLOGY		MOV
NETWORK CONFIGURATION		2 wires
CONNECTION METHOD		Screw Terminal (8-12AWG)
MOUNTING		DIN RAIL
MATERIAL		Thermoplastic UL94-V0
NEMA RATING (IP RATING)		NEMA 2 (IP20)
FAIL-SAFE BEHAVIOR		Disconnection via fuse-link
REAL-TIME DIAGNOSTICS		Visual indicator and remote contacts
DIMENSIONS		See diagram (mm)
WEIGHT		0.30 lbs
SPARE PART		DMS40-400
Standards		
Certification		UL Listed / EAC / TUV
UL STANDARD		UL1449 5th Edition
UL CATEGORY		VZCA, VZCA7
UL FILE NUMBER		E326289
STANDARDS		IEC 61643-11, NOM-003-SCFI-2014, NOM-001-SCFI-1993
ENVIRONMENTAL STANDARDS		ROHS
Part number		
3314111		