


- Quickly attaches conduit to beams.
- Fasteners will rotate 360°.
- Simply installed with a hammer.

## Push-Type Conduit To Beam Fasteners



UPC/Part Number	Catalog Number	Conduit Size	Flange Thickness	Box Qty.
78101119310	<b>BP-8-U-2-4</b>	½" EMT	⅛" - ¼"	100
78101119315	<b>BP-8-U-5-8</b>	½" EMT	⅝" - ½"	100
78101119320	<b>BP-8-U-9-12</b>	½" EMT	⅞" - ¾"	100
78101119405	<b>BP-12-U-2-4</b>	¾" EMT ½" IMC, Rigid	⅛" - ¼"	100
78101119410	<b>BP-12-U-5-8</b>	¾" EMT ½" IMC, Rigid	⅝" - ½"	100
78101119415	<b>BP-12-U-9-12</b>	¾" EMT ½" IMC, Rigid	⅞" - ¾"	100
78101119490	<b>BP-16-U-2-4</b>	1" EMT ¾" IMC, Rigid	⅛" - ¼"	100
78101119495	<b>BP-16-U-5-8</b>	1" EMT ¾" IMC, Rigid	⅝" - ½"	100
78101119500	<b>BP-16-U-9-12</b>	1" EMT ¾" IMC, Rigid	⅞" - ¾"	100

**Ultimate  
Static Load  
Capacity**

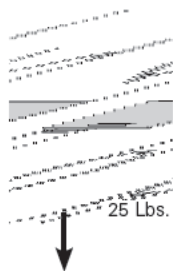

*Read safety/installation instruction sheets in packages before use.  
These products are designed for positioning only. No load rating.*