


# Conduit & cable



- For use with ½" thru 4" Conduit.
- Static Load Capacity: 400 lbs.
- Material: Type 304 Stainless Steel.

## Stainless Steel Conduit Hangers

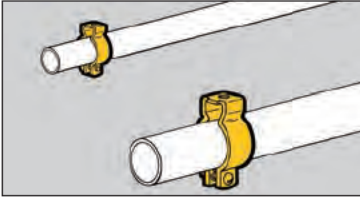

With Bolt And Nut

UPC/Part Number	Catalog Number	Trade Size	Conduit Size EMT	Size Rigid	Box Qty.
78101119800	<b>BL1400-SS4*</b>	0	½"	½"	100
78101119801	<b>BL1410-SS4*</b>	1	¾"	¾"	100
78101119802	<b>BL1420-SS4*</b>	2	1"	1"	100
78101119803	<b>BL1425-SS4*</b>	2.5	1¼"	--	100
78101119804	<b>BL1430-SS4*</b>	3	1½"	1¼"	100
78101119805	<b>BL1440-SS4†</b>	4	--	1½"	50
78101119806	<b>BL1450-SS4†</b>	5	2"	2"	50
78101119807	<b>BL1460-SS4†</b>	6	2½"	2½"	25
78101119808	<b>BL1470-SS4†</b>	7	3"	3"	25
78101119809	<b>BL1480-SS4†</b>	8	3½"	3½"	10
78101119810	<b>BL1490-SS4†</b>	9	4"	4"	10

\* 9/32" mounting hole. † 11/32" mounting hole.

*Read safety/installation instruction sheets in packages before use.*