
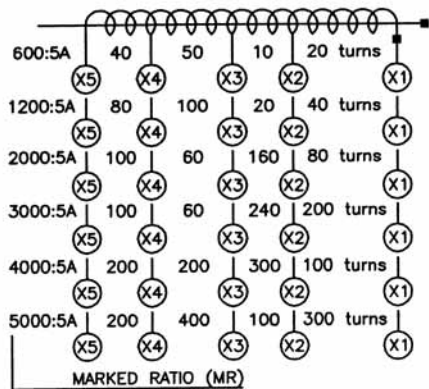
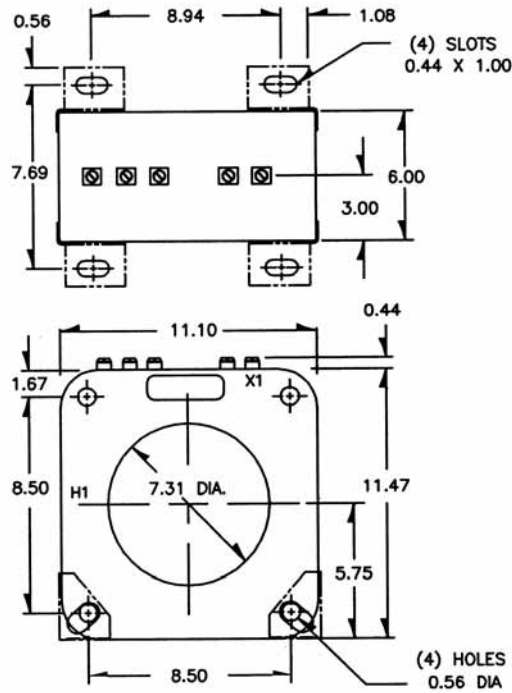


Model 143MR

Window Diameter 7.13"

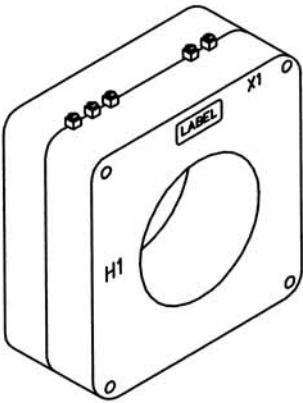

Application:
Relaying

Frequency:
50 – 400Hz:


Insulation Level:
600 Volts, 10kV BIL full wave

Continuous Thermal Current Rating Factor:
See TRF at curve

- Terminals are brass studs No. 10 – 32 with one flat washer, lockwasher and regular nut
- The transformer winding is arranged so that the turns are fully distributed between all taps
- Order mounting bracket kit separately
- Approximate weight: 60 lbs


Approvals

UL [®] **US** **UL 257877**
CSA 223647

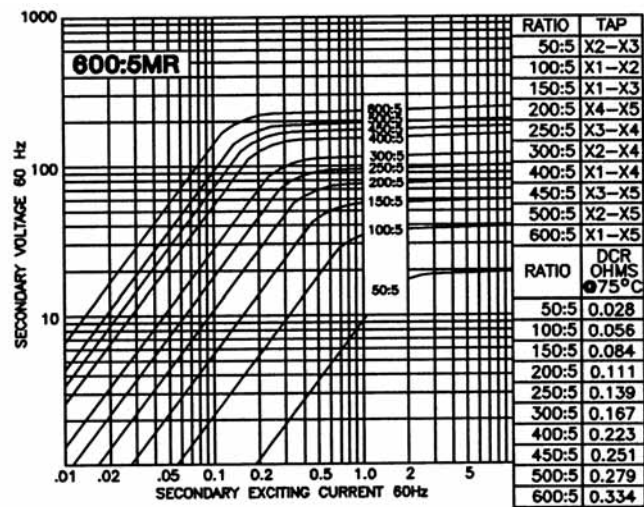


Model 143-601MR - rating C200

TRF= 2.0 • 30°C, 1.5 • 55°C amb.

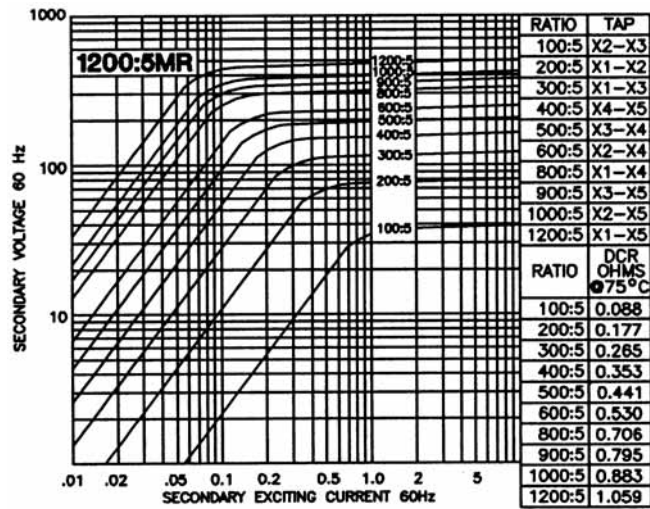


Model 143-122MR - rating C400

TRF= 1.5 • 30°C, 1.0 • 55°C amb.

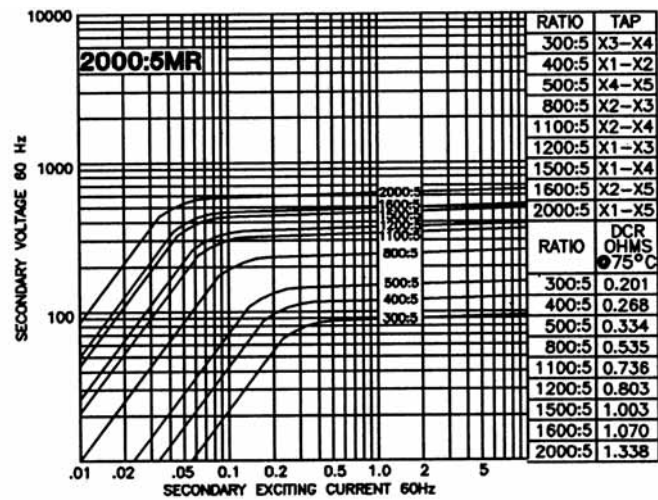


Model 143-202MR - rating C400

TRF= 1.33 • 30°C, 1.0 • 55°C amb.

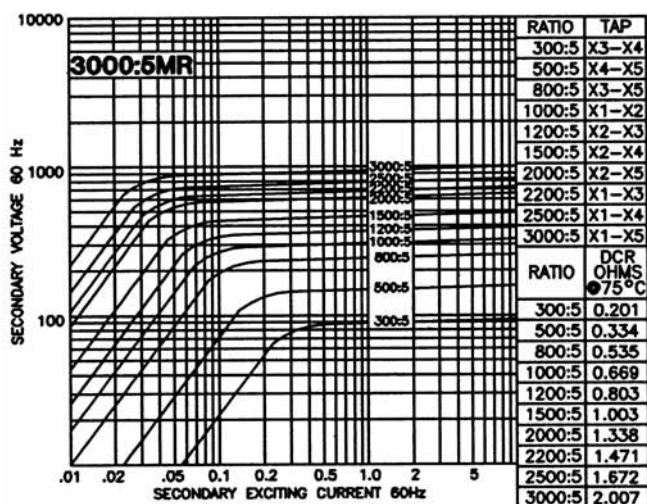


Model 143-302MR - rating C800

TRF= 1.0 @ 30°C, 0.8 @ 55°C amb.

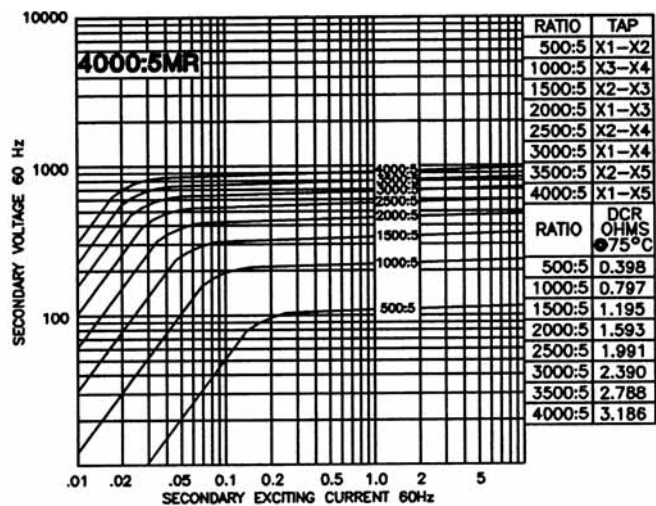

Model 143-402MR - rating C800

TRF= 1.0 @ 30°C, 0.6 @ 55°C amb.

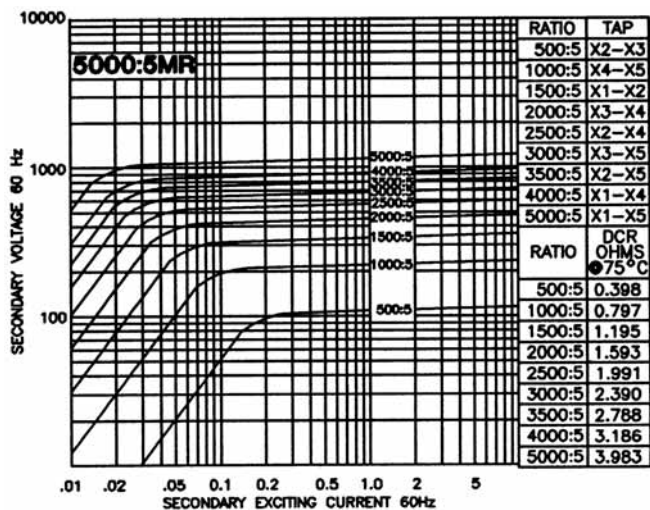

Model 143-502MR - rating C800

TRF= 1.0 @ 30°C, 0.6 @ 55°C amb.