

Model 13

**Application:**

For current to voltage conversion by use of a loading resistor.

**Frequency:**

50-400Hz

**Insulation Level:**

600 Volts, 10kV BIL full wave

**Continuous Thermal Current Rating Factor:**

200A at 30°C amb,  
120A at 55°C amb

- Approximate weight: 0.1-0.2 lbs


Approvals



# Model 13

**Window Diameter 0.56"**

This lightweight, miniature current transformer is suitable for direct mounting on printed circuit boards. The graphs below illustrate the voltage output capacity of each, and over the ranges shown, will maintain a  $\pm 3\%$  linearity.

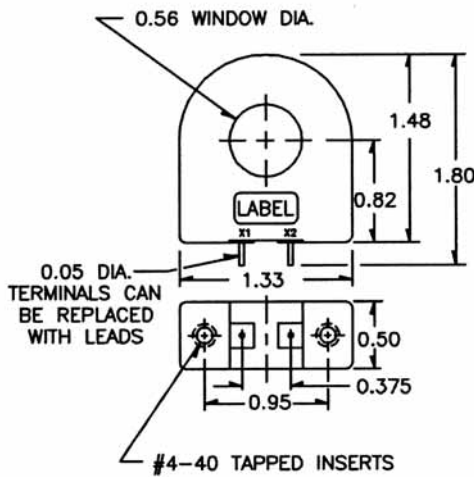

**Typical Performance Characteristics**

