



3½" NONMETALLIC CEILING BOXES

27/8" DEEP


Weight limit is 50 lbs for fixture except where indicated.

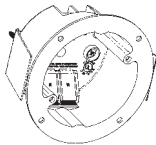


TP16200,
(TP16201 – 27/8" Deep)
Old Work

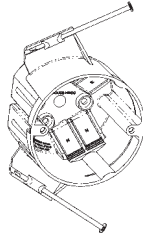

TP16310
TP16311

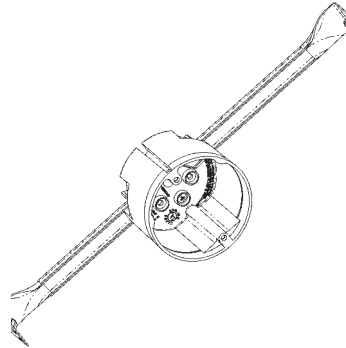

TP16307
TP16308

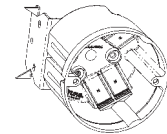

TP16317
TP16318

Nonmetallic Ceiling Boxes

Cat. #	Clamps	Ground Plate	Bracket/Bar Hgr.	Capacity Cu. In.	No. of Clamp Openings	Std. Unit Pkg.	Wt. Lbs. Per 100
TP16200†	Yes	—	Snap	16.0	4	50	27
TP16201†	Yes	Yes	Snap	16.0	4	50	29
TP16310*	Yes	—	Nails	19.3	4	50	18
TP16311*	Yes	Yes	Nails	19.3	4	50	20
TP16307*‡	Yes	—	14"–22-1/2"	19.3	4	25	57
TP16308*‡	Yes	Yes	14"–22-1/2"	19.3	4	25	59
TP16317*	Yes	—	"B"	19.3	4	50	26
TP16318*	Yes	Yes	"B"	19.3	4	50	20

*Nail Bracket is set 19/16" back from the face of the box.

† Weight limit 15lbs for ceiling mounted fixtures and 6lbs for wall mounted fixtures.

‡ Weight limit 15lbs at 24" stud spacing, 35lbs at 16" stud spacing.

LAMPHOLDER



TP16098



TP16099

Standard Materials:


- Plastic molded of heat and impact resistant material that prevents discoloring and reduces breakage

Cat. #	Description	Std. Unit Pkg.	Wt. Lbs. Per 100
TP16098	Lampholder, Pull Chain	50	29
TP16099	Lampholder, Keyless, feed thru	50	23


4" NONMETALLIC CEILING BOXES

Weight limit is 50 lbs for fixture except where indicated


Nonmetallic Ceiling Boxes

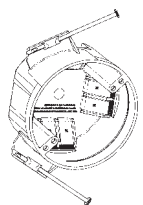


TP16111, TP16110

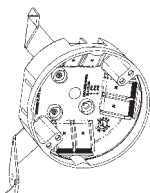


TP16012, TP16112

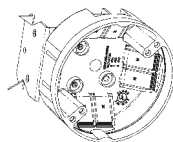

TP16007, TP16107

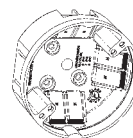

TP16002

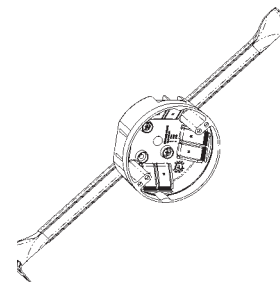

TP16022, TP16122


Cat. #	Clamps	Ground Plate	Bracket/Bar Hgr.	Capacity Cu. In.	No. of Cable Pry-outs	Std. Unit Pkg.	Wt. Lbs. Per 100
1½" DEEP							
TP16002	Yes	—	—	14.8	4	50	12
TP16003	Yes	Yes	—	14.8	4	50	14
TP16012	Yes	—	"V"	14.8	4	50	24
TP16013	Yes	Yes	"V"	14.8	4	50	26
TP16007	Yes	—	"B"	14.8	4	50	26
TP16008	Yes	Yes	"B"	14.8	4	50	28
TP16022*	Yes	—	14"-22-1/2"	14.8	4	25	56
TP16023*	Yes	Yes	14"-22-1/2"	14.8	4	25	58
2¼" DEEP							
TP16111	Yes	—	Nails	22.5	4	50	19
TP16110	Yes	Yes	Nails	22.5	4	50	21
TP16112	Yes	—	"V"	20.8	4	50	27
TP16113	Yes	Yes	"V"	20.8	4	50	29
TP16107	Yes	—	"B"	20.8	4	50	28
TP16108	Yes	Yes	"B"	20.8	4	50	30
TP16122*	Yes	—	14"-22-1/2"	20.8	4	20	59
TP16123*	Yes	Yes	14"-22-1/2"	20.8	4	20	61

*Weight limit 15 lbs at 24" stud spacing, 35 lbs at 16" stud spacing.

4" NONMETALLIC CEILING FAN BOXES

With clamps for nonmetallic cable.

All mounting hardware supplied, suitable for support of fans weighing up to 35 lbs.

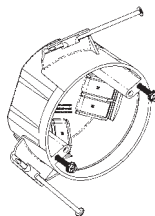

TP16511

Cat. #	Diameter	Mounting Method	Capacity Cu. In.	No. of Clamp Openings	Std. Unit Pkg.	Wt. Lbs. Per 100
TP16511	4"	Nails only	20.8	6	25	21