




4" SQUARE OUTLET BOXES – 22.0 CUBIC INCH CAPACITY
1½" DEEP
FOR ARMORED & METAL CLAD (MCI) CABLE – CLAMPS IN EACH END

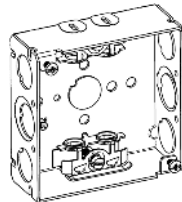


TP454

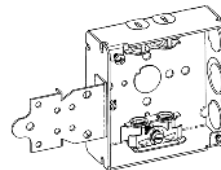

TP456

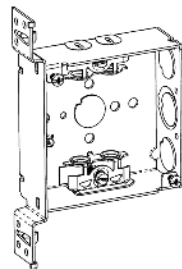

TP459

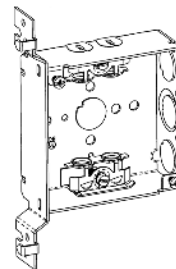

TP461

Product Number	Metal Stud Sizes	Bracket	Description	KNOCKOUTS		Std. Unit Pkg.	Wt. Lbs. Per 100
				Sides	Bottom		
TP459	All	"VMS"	Welded	4-Cable, 2-1/2", 1-1/2" & 3/4"-E	1-1/2"	25	89
TP454	—	—	Welded	4-Cable, 4-1/2", 2-1/2" & 3/4"-E	1-1/2"	50	81
TP456	—	"F", Set Flush	Welded	4-Cable, 2-1/2", 1-1/2" & 3/4"-E	1-1/2"	25	92
TP461	—	"VP"	Welded	4-Cable, 2-1/2", 1-1/2" & 3/4"-E	1-1/2"	25	89