

EVI Series Explosionproof Incandescent Luminaires


Photometric Data

2L

Factory Sealed
100-500W Medium and Mogul Base


Medium Base

Luminaire with Globe and Guard
EVICX2301 Lamp: 300W/PS25 Incandescent

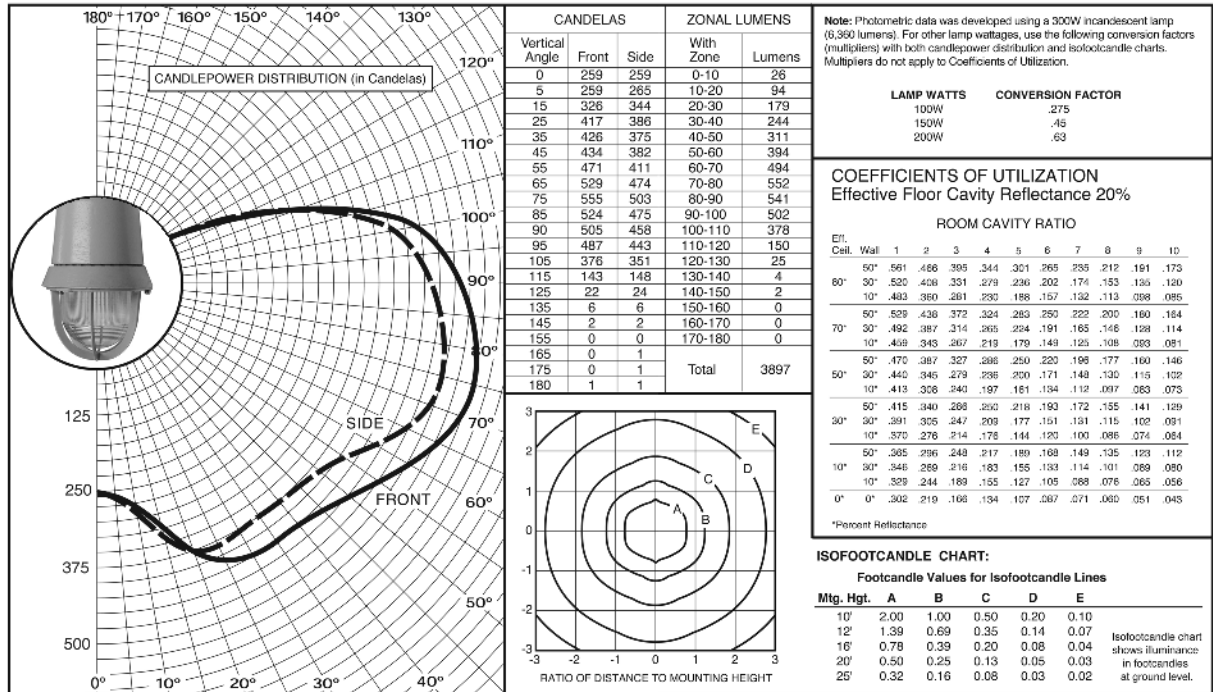

Medium Base


Luminaire with Globe and Dome Reflector (Less Guard)
EVICX2300 Lamp: 300W/PS25 Incandescent

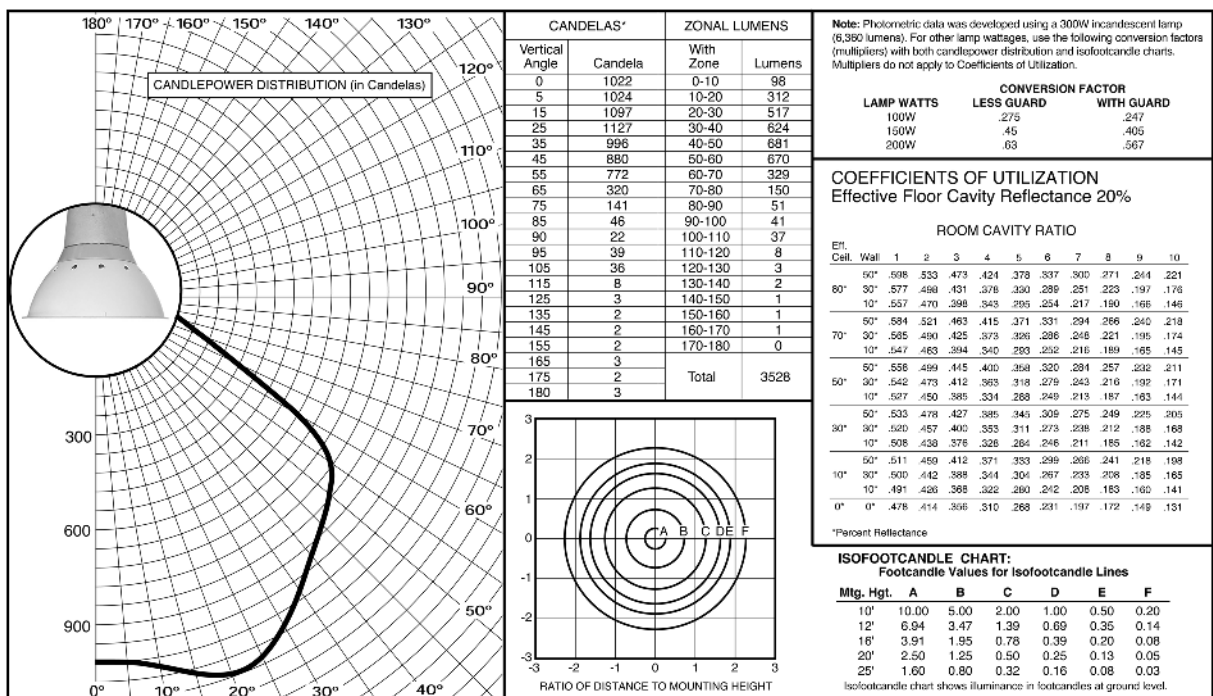

Factory Sealed 100-500W Medium and Mogul Base


Medium Base

Luminaire with Globe and 30° Angle Reflector (Less Guard)
EVICX2300 Lamp: 300W/PS25 Incandescent

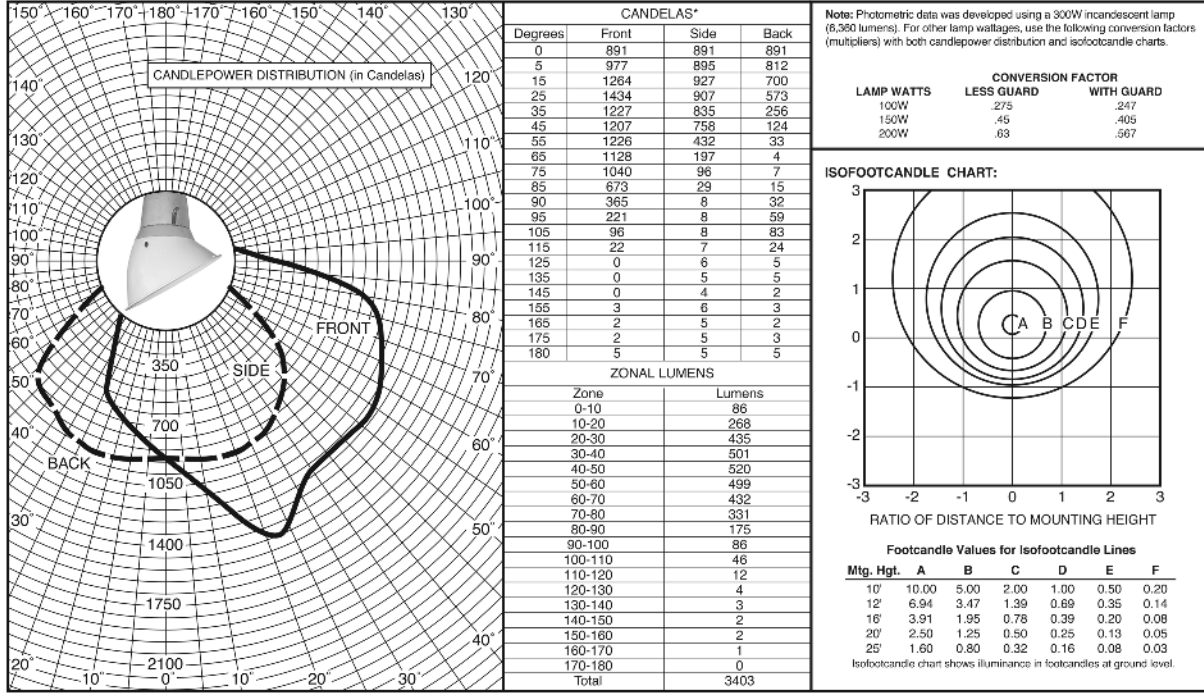

Mogul Base

Luminaire with Globe and Guard
EVIA2501 Lamp: 500W/PS40 Incandescent

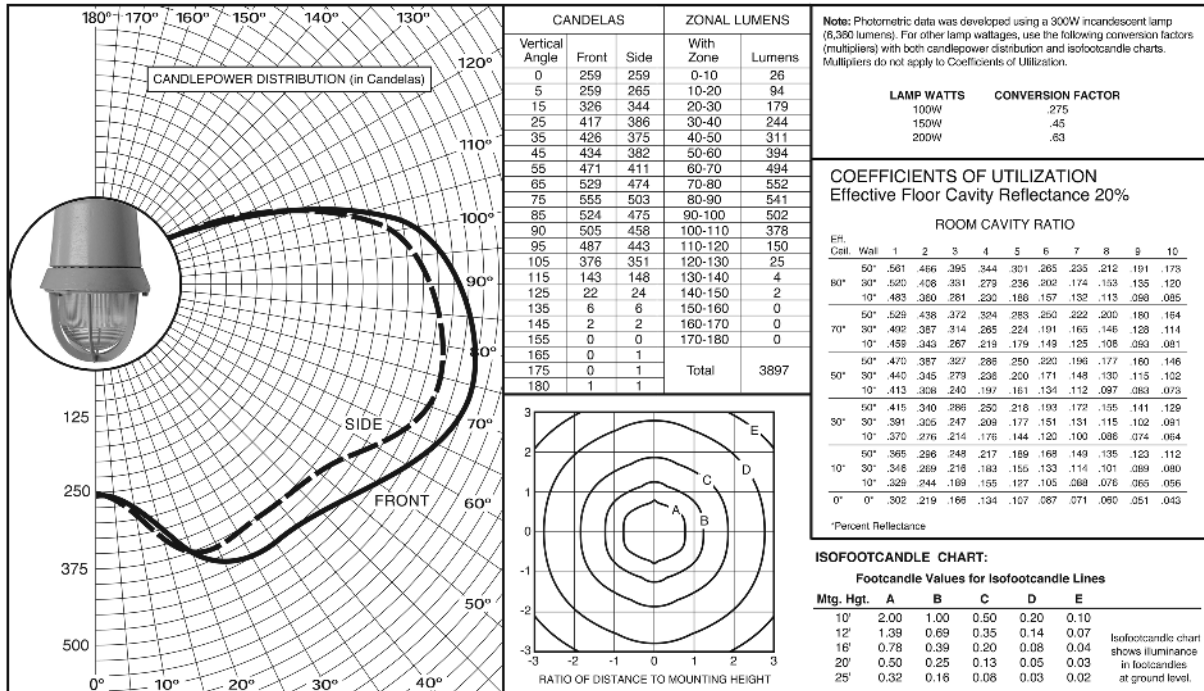

EVI Series Explosionproof Incandescent Luminaires


Photometric Data

2L

Factory Sealed
100-500W Medium and Mogul Base

Mogul Base

Luminaire with Globe and Dome Reflector (Less Guard)
EVI2500 Lamp: 500W/PS40 Incandescent

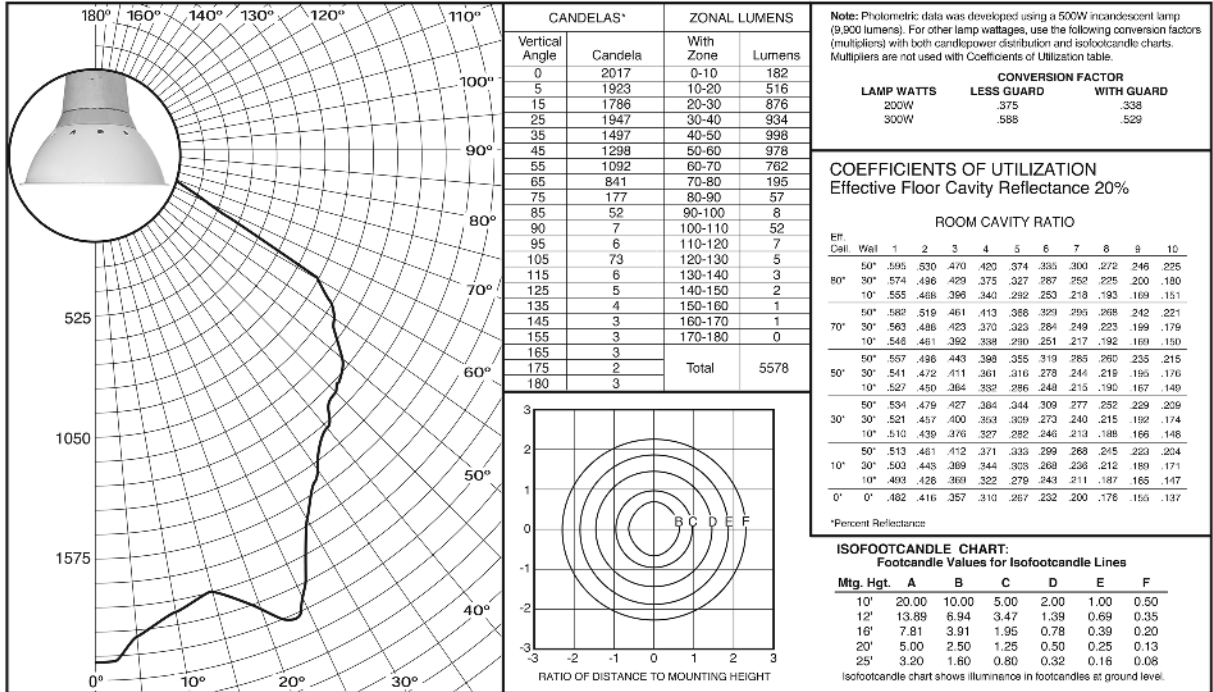

Mogul Base

Luminaire with Globe and Angle Reflector (Less Guard)
EVI2500 Lamp: 500W/PS40 Incandescent

