



RED PLASTIC CONICAL ANCHORS


Installation

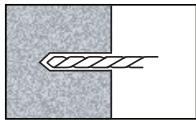


1. Drill proper size hole, 1/4" deeper than anchor length.

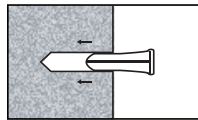

2. Insert anchor flush with surface of wall.

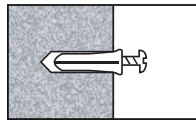

3. Insert wood or sheet metal screw through fixture and tighten.

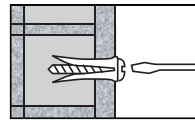

4. Anchor expands as wood or sheet metal screw is driven in.



Gravity Feed Jar				
Description	Drill Size	Part #	Jar Qty	Master Carton
#6-8 Red Conical	1/8"	59408J ★	100	600
#8-10 Red Conical	3/16"	59410J ★	100	600
#10-12 Red Conical	1/4"	59412J ★	100	600
#14-16 Red Conical	5/16"	59414J ★	100	600

All plastic anchor Jars include a masonry drill bit.

★ Made in USA

Description	Kits	Gravity Feed Jar
	Part #	Part #
#6 Slot/Phil Pan Head Red Conical Anchor Kit Includes 1/8" Carbide Bit		
#6 x 1" Screws (100 Pieces)	39816	39816J
#6-8 Anchors (100 Pieces)	(201 Piece Kit)	(201 Piece Kit)
#8 Square Drive Pan Head Red Conical Anchor Kit Includes 3/16" Carbide Bit		
#8 x 1" Screws (100 Pieces)	39708	—
#8-10 Anchors (100 Pieces)	(201 Piece Kit)	
#8 Slot/Phil Pan Head Red Conical Anchor Kit Includes 3/16" Carbide Bit		
#8 x 1" Screws (100 Pieces)	39818	39819J
#8-10 Anchors (100 Pieces)	(201 Piece Kit)	(201 Piece Kit)
#8 Hex Washer Head Red Conical Anchor Kit Includes 3/16" Carbide Bit		
#8 x 1" Screws (100 Pieces)	39908	—
#8-10 Anchors (100 Pieces)	(201 Piece Kit)	

Continued on next page.