


Conduit/Cable

•No fastener required.

•Available both non-keyholed and keyholed for 1/4"-20 screw.

•Ultimate Static Load Limit:
25 lbs vertical position
15 lbs horizontal position

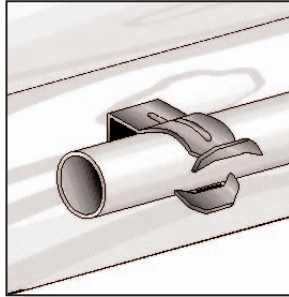

Conduit Clip



HIC75




HIC75T

Catalog Number	Fits		Standard Package
	EMT	Rigid/IMC	
HIC50	1/2"	---	100
HIC75	3/4"	1/2"	100
HIC100	1"	3/4"	100

Catalog Number	With Thread Impression for 1/4"-20		Standard Package
	EMT	Rigid/IMC	
HIC50T	1/2"	---	100
HIC75T	3/4"	1/2"	100
HIC100T	1"	3/4"	100


Static Load Limit

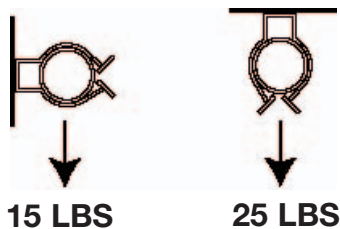

•No fastener required.


•Available both non-keyholed and keyholed for 1/4"-20 screw.

•Ultimate Static Load Limit:
100 lbs vertical position
25 lbs horizontal position

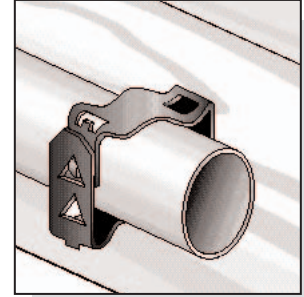

Conduit Clip

Static Load Limit

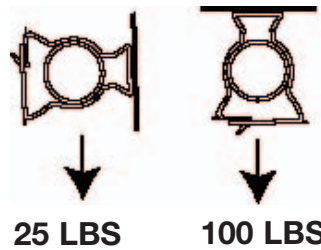

25 LBS

100 LBS



KC1234



KC1234T

Catalog Number	Fits Conduit		Standard Package
KC38	3/8"		100
KC1234	1/2", 3/4"		100
KC1	1"		100
KC114	1-1/4"		100
KC112	1-1/2"		100
KC2	2"		100

Catalog Number	With Thread Impression for 1/4"-20		Standard Package
KC38T	3/8"		100
KC1234T	1/2", 3/4"		100
KC1T	1"		100
KC114T	1-1/4"		100
KC112T	1-1/2"		100
KC2T	2"		100

- When ordering less than a standard package, there is a 25% minimum surcharge.
- When ordering, please use catalog number. For shipping weight, see the index.
- For product samples, please fax our Marketing Department.