

82306**3/8 X 18 BELLHANGER DRILL**

UPC: 085937823069

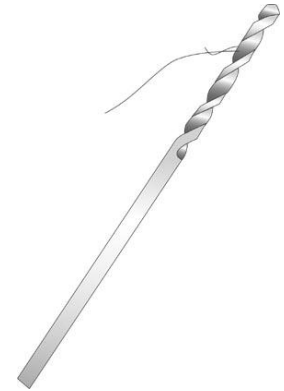
Country of Origin:

UNSPSC: 23241634

Taiwan

Commodity: Jobber length drill

The Carbide Tipped Bell Hanger is designed for making holes and fishing wire through these holes for all electrical, telephone, security-alarm, structured wiring systems or any small wire installation.

**Product Attributes**

Brand Name	Minerallac Company
Sub Brand	Cully
Type	Bellhanger Bit
Special Features	Hole in head of bit for easy pulling of wire.
Application	To drill into wood
Standard	N/A
Grade	N/A
Material	Middle Carbon Steel
Finish	Polished
Point Type	Non-screw Tip
Drill Point	82°
Fractional Size	3/8" IN
Flute Length	4" IN
Overall Length	18" IN
Shank Diameter	3/8" IN
Shank Type	Round Shank
Number of Pieces	1

Item Status: Active

Standard Qty: 1

Minerallac Company

Tel: 800-927-3293

Fax: 800-824-8942

www.minerallac.com