

86928

(785-1-3/4) 1-3/4" SAW TOOTH B


UPC: 085937869289

Country of Origin:

UNSPSC: 27111542

USA

Commodity: Spur point bit

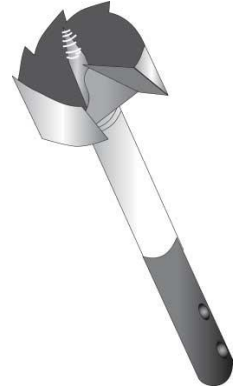

These boring bits have multiple spurs which scribe the periphery of the hole in advance of the cutting edges to guide the bit in the proper direction.

Product Attributes

Brand Name	Minerallac Company
Sub Brand	Cully
Type	Self-Feeding, Multi-spur Bit
Special Features	Open design wicks away wood chips.
Application	Perfect for boring through veneers, overlapping holes, or on close centers.
Standard	N/A
Bit Diameter	N/A
Overall Length	5" IN
Shank Size	7/16" IN
Drill Size	1-3/4" IN
Shank Type	Hex Shank
Number Of Points	Multiple Points
Number Of Flutes	1
Material	Steel
Finish	Polished Finish

Item Status: Active

Standard Qty: 1

Minerallac Company

Tel: 800-927-3293

Fax: 800-824-8942

www.minerallac.com