

**91606****9/64 HSS JOBBER DRILL**


UPC: 085937916068

Country of Origin:

UNSPSC: 23241634

**China**

Commodity: Jobber length drill

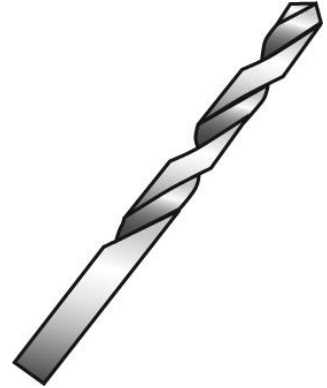

*HSS Jobber Drills are jobber-length drill bits, made from high-speed steel, that have a polished flute for easy chip removal.*

**Product Attributes**

|                  |                                                  |
|------------------|--------------------------------------------------|
| Brand Name       | Minerallac Company                               |
| Sub Brand        | Cully                                            |
| Type             | Jobber Drill                                     |
| Special Features | Features a polished flute for easy chip removal. |
| Application      | General Purpose                                  |
| Standard         | N/A                                              |
| Grade            | N/A                                              |
| Material         | Steel                                            |
| Finish           | Two-tone                                         |
| Point Type       | Standard                                         |
| Drill Point      | 118°                                             |
| Fractional Size  | 9/64" IN                                         |
| Flute Length     | 1-3/4" IN                                        |
| Overall Length   | 2-7/8" IN                                        |
| Shank Diameter   | 9/64" IN                                         |
| Number of Pieces | 1                                                |

Item Status: Active

Standard Qty: 12

**Minerallac Company**

Tel: 800-927-3293

Fax: 800-824-8942

[www.minerallac.com](http://www.minerallac.com)