

91611

7/32 HSS JOBBER DRILL

UPC: 085937916112


Country of Origin:

UNSPSC: 23241634

China

Commodity: Jobber length drill

HSS Jobber Drills are jobber-length drill bits, made from high-speed steel, that have a polished flute for easy chip removal.

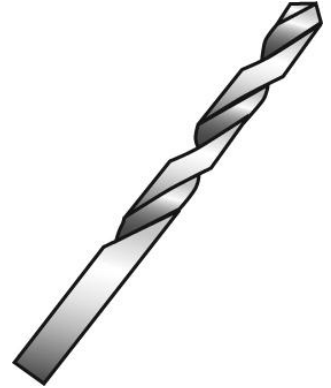

Product Attributes

Brand Name	Minerallac Company
Sub Brand	Cully
Type	Jobber Drill
Special Features	Features a polished flute for easy chip removal.
Application	General Purpose
Standard	N/A
Grade	N/A
Material	Steel
Finish	Bright
Point Type	Standard
Drill Point	118°
Fractional Size	7/32" IN
Flute Length	2-1/2" IN
Overall Length	3-3/4" IN
Shank Diameter	7/32" IN
Number of Pieces	1

Item Status: Active

Standard Qty: 12

Minerallac Company

Tel: 800-927-3293

Fax: 800-824-8942

www.minerallac.com