

91618

21/64 HSS JOBBER DRILL


UPC: 085937916181

Country of Origin:

UNSPSC: 23241634

China

Commodity: Jobber length drill

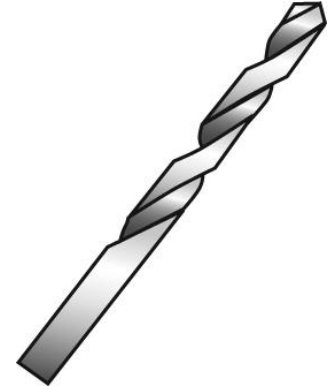

HSS Jobber Drills are jobber-length drill bits, made from high-speed steel, that have a polished flute for easy chip removal.

Product Attributes

Brand Name	Minerallac Company
Sub Brand	Cully
Type	Jobber Drill
Special Features	Features a polished flute for easy chip removal.
Application	General Purpose
Standard	N/A
Grade	N/A
Material	Steel
Finish	Bright
Point Type	Standard
Drill Point	118°
Fractional Size	21/64" IN
Flute Length	3-5/16" IN
Overall Length	4-5/8" IN
Shank Diameter	21/64" IN
Number of Pieces	1

Item Status: Active
Standard Qty: 6

Minerallac Company

Tel: 800-927-3293
Fax: 800-824-8942
www.minerallac.com