

91628**31/64 HSS JOBBER DRILL**

UPC: 085937916280

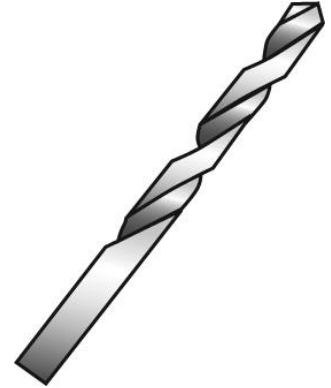
Country of Origin:

UNSPSC: 23241634

Taiwan

Commodity: Jobber length drill

HSS Jobber Drills are jobber-length drill bits, made from high-speed steel, that have a polished flute for easy chip removal.

**Product Attributes**

Brand Name	Minerallac Company
Sub Brand	Cully
Type	Jobber Drill
Special Features	Features a polished flute for easy chip removal.
Application	General Purpose
Standard	N/A
Grade	N/A
Material	Steel
Finish	Two-tone
Point Type	Standard
Drill Point	118°
Fractional Size	31/64" IN
Flute Length	4-3/8" IN
Overall Length	5-7/8" IN
Shank Diameter	31/64" IN
Number of Pieces	1

Item Status: Active

Standard Qty: 6

Minerallac Company

Tel: 800-927-3293

Fax: 800-824-8942

www.minerallac.com