

91906

9/64 HSS JOBBER SPLIT POINT


UPC: 085937919069

Country of Origin:

UNSPSC: 23241634

Taiwan

Commodity: Jobber length drill

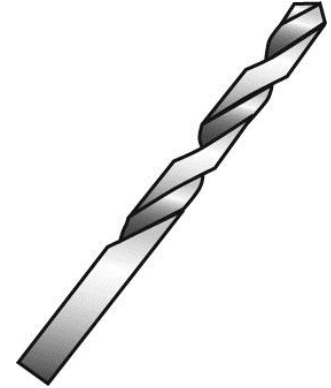

HSS Jobber Drills are jobber-length drill bits, made from high-speed steel, that have a polished flute for easy chip removal.

Product Attributes

Brand Name	Minerallac Company
Sub Brand	Cully
Type	Jobber Drill
Special Features	Features a polished flute for easy chip removal.
Application	General Purpose
Standard	N/A
Grade	N/A
Material	Steel
Finish	Black Oxide
Point Type	Split Point
Drill Point	135°
Fractional Size	9/64" IN
Flute Length	1-3/4" IN
Overall Length	2-7/8" IN
Shank Diameter	9/64" IN
Number of Pieces	1

Item Status: Active
Standard Qty: 12

Minerallac Company

Tel: 800-927-3293
Fax: 800-824-8942
www.minerallac.com