

91907**5/32 HSS JOBBER SPLIT POINT**

UPC: 085937919076

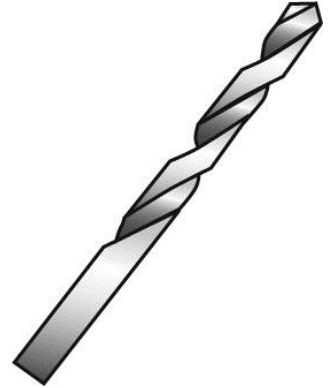
Country of Origin:

UNSPSC: 23241634

Taiwan

Commodity: Jobber length drill

HSS Jobber Drills are jobber-length drill bits, made from high-speed steel, that have a polished flute for easy chip removal.

**Product Attributes**

Brand Name	Minerallac Company
Sub Brand	Cully
Type	Jobber Drill
Special Features	Features a polished flute for easy chip removal.
Application	General Purpose
Standard	N/A
Grade	N/A
Material	Steel
Finish	Black Oxide
Point Type	Split Point
Drill Point	135°
Fractional Size	5/32" IN
Flute Length	2" IN
Overall Length	3-1/8" IN
Shank Diameter	5/32" IN
Number of Pieces	1

Item Status: Active

Standard Qty: 12

Minerallac Company

Tel: 800-927-3293

Fax: 800-824-8942

www.minerallac.com