

91919

11/32 HSS JOBBER SPLIT POINT


UPC: 085937919199

Country of Origin:

UNSPSC: 23241634

**Taiwan**

Commodity: Jobber length drill

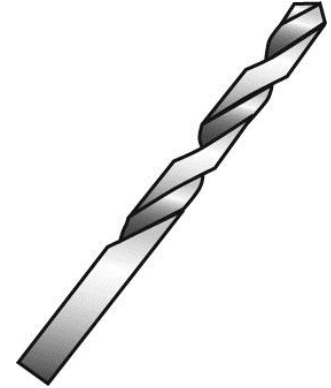

*HSS Jobber Drills are jobber-length drill bits, made from high-speed steel, that have a polished flute for easy chip removal.*

**Product Attributes**

Brand Name	Minerallac Company
Sub Brand	Cully
Type	Jobber Drill
Special Features	Features a polished flute for easy chip removal.
Application	General Purpose
Standard	N/A
Grade	N/A
Material	Steel
Finish	Black Oxide
Point Type	Split Point
Drill Point	135°
Fractional Size	11/32" IN
Flute Length	3-7/16" IN
Overall Length	4-3/4" IN
Shank Diameter	11/32" IN
Number of Pieces	1

Item Status: Active

Standard Qty: 6

Minerallac Company

Tel: 800-927-3293

Fax: 800-824-8942

www.minerallac.com