


Specifications



Photo is representative

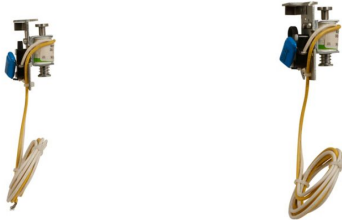

Eaton SNT4LP18K

Eaton molded case circuit breaker accessory shunt trip, Fixed shunt trip, 480-600 V, Pigtail leads, Frame J-K

General specifications

PRODUCT NAME	Eaton molded case circuit breaker enclosure
CATALOG NUMBER	SNT4LP18K
UPC	782114621905
PRODUCT LENGTH/DEPTH	4 in
PRODUCT HEIGHT	2 in
PRODUCT WIDTH	2 in
PRODUCT WEIGHT	4 lb
WARRANTY	Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.
CERTIFICATIONS	UL Listed



Powering Business Worldwide

Product specifications

TYPE	Fixed shunt trip
VOLTAGE RATING	480-600V
FRAME SIZE	Frame J-K
MOUNTING METHOD	Left
CONNECTION	Pigtail leads

Resources

	Application of Tap Rules to Molded Case Breaker Terminals
APPLICATION NOTES	UL listed 100%-rated molded case circuit breakers Application of Multi-Wire Terminals for Molded Case Circuit Breakers
BROCHURES	Plug-in adapters for molded case circuit breakers product aid Motor protection circuit breakers product aid Circuit breaker motor operators product aid StrandAble terminals product aid Current limiting Series C molded case circuit breakers product aid Power metering and monitoring with Modbus RTU product aid Multi-wire lugs product aid Breaker service centers
CATALOGS	Circuit Protection, Molded Case Circuit Breakers, Volume 4, Tab 2
MULTIMEDIA	Flex shaft handle installation tutorial MOEM MCCB product selection guide Series C G-Frame molded case circuit breakers time current curves
SPECIFICATIONS AND DATASHEETS	Series C J-Frame molded case circuit breakers time current curves Eaton Specification Sheet - SNT4LP18K Series C F-Frame molded case circuit breakers

PROJECT NAME:

PROJECT NUMBER:

PREPARED BY:

DATE:



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

Follow us on social media to get the latest product and support information.



© 2025 Eaton. All Rights Reserved.