

Eaton XT IEC contactor

CE55BN3AB

UPC:782113779829

Dimensions:

- **Height:** 2.96 IN
- **Length:** 3.28 IN
- **Width:** 4.2 IN

Weight:2.55 LB

Notes:No enclosure

Warranties:

- Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

Specifications:


- **Amperage Rating:** 10A
- **Coil Voltage:** 110-120 Vac, 50-60 Hz
- **Contact Configuration:** 1NC
- **Frame Size:** 45 mm
- **Frequency Rating:** 50-60 Hz
- **Max Hp Rating:** 0.5 hp
- **Mounting:** Top mounted auxiliary contacts
- **Number Of Poles:** Three-pole
- **Operation:** Reversing
- **Relay:** No overload relay
- **Series:** Freedom
- **Type:** Contactor

Supporting documents:

- [Eaton's Volume 5-Motor Control and Protection](#)
- [Eaton Specification Sheet - CE55BN3AB](#)

Certifications:

- CSA Certified
- IEC Rated
- UL Listed

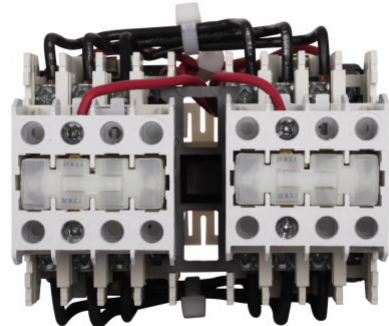

Product compliance:

- ISO 9000
- DIN VDE 0600

© 2016 Eaton. All rights reserved.