

## Eaton XT IEC contactor

**CE55DN3CB**

**UPC:**782113780047

**Dimensions:**

- **Height:** 2.96 IN
- **Length:** 3.28 IN
- **Width:** 4.2 IN

**Weight:**2.25 LB

**Notes:**No enclosure

**Warranties:**

- Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

**Specifications:**

- **Amperage Rating:** 18A
- **Coil Voltage:** 440-480 Vac, 50-60 Hz
- **Contact Configuration:** 1NC
- **Frame Size:** 55 mm
- **Frequency Rating:** 50-60 Hz
- **Mounting:** Top mounted auxiliary contacts
- **Number Of Poles:** Three-pole
- **Operation:** Reversing
- **Relay:** No overload relay
- **Series:** Freedom
- **Type:** Contactor


**Supporting documents:**

- [Eaton's Volume 5-Motor Control and Protection](#)
- [Eaton Specification Sheet - CE55DN3CB](#)

**Certifications:**

- CSA Certified
- IEC Rated
- UL Listed

**Product compliance:**

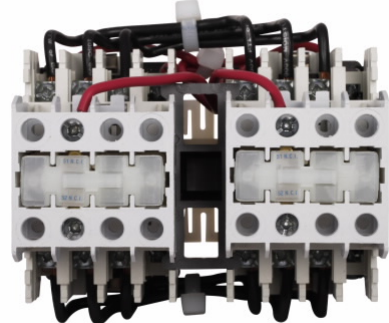

- DIN VDE 0600
- ISO 9000

---

© 2016 Eaton. All rights reserved.