

Eaton XT IEC contactor

CE55FN3BB

UPC:782113411781

Dimensions:

- **Height:** 2.96 IN
- **Length:** 3.28 IN
- **Width:** 4.2 IN

Weight:2.25 LB

Notes:No enclosure

Warranties:

- Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

Specifications:


- **Amperage Rating:** 32A
- **Coil Voltage:** 220-240 Vac, 50-60 Hz
- **Contact Configuration:** 1NC
- **Frame Size:** 90 mm
- **Frequency Rating:** 50-60 Hz
- **Max Hp Rating:** 5 hp
- **Mounting:** Top mounted auxiliary contacts
- **Number Of Poles:** Three-pole
- **Operation:** Reversing
- **Relay:** No overload relay
- **Series:** Freedom
- **Type:** Contactor

Supporting documents:

- [Eatons Volume 5-Motor Control and Protection](#)
- [Motor Starters and Contactors - Low Voltage Catalog](#)
- [Eaton Specification Sheet - CE55FN3BB](#)

Certifications:

- CSA Certified

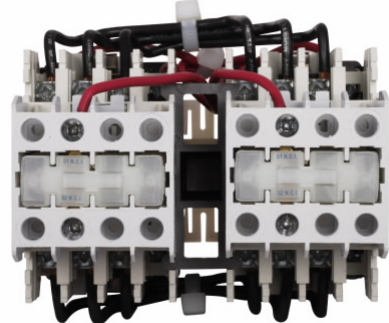

- IEC Rated
- UL Listed

Product compliance:

- ISO 9000
- DIN VDE 0600

© 2016 Eaton. All rights reserved.