

## Eaton XT IEC contactor

**CE55GN3AB**

**UPC:**782113973487

**Dimensions:**

- **Height:** 5.05 IN
- **Length:** 4.44 IN
- **Width:** 5.71 IN

**Weight:**7.15 LB

**Notes:**No enclosure

**Warranties:**

- Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

**Specifications:**


- **Amperage Rating:** 37A
- **Coil Voltage:** 110-120 Vac, 50-60 Hz
- **Contact Configuration:** 1NC
- **Frame Size:** 90 mm
- **Frequency Rating:** 50-60 Hz
- **Max Hp Rating:** 3 hp
- **Mounting:** Top mounted auxiliary contacts
- **Number Of Poles:** Three-pole
- **Operation:** Reversing
- **Relay:** No overload relay
- **Series:** Freedom
- **Type:** Contactor

**Supporting documents:**

- [Eaton's Volume 5-Motor Control and Protection](#)
- [Eaton Specification Sheet - CE55GN3AB](#)

**Certifications:**

- IEC Rated
- UL Listed
- CSA Certified

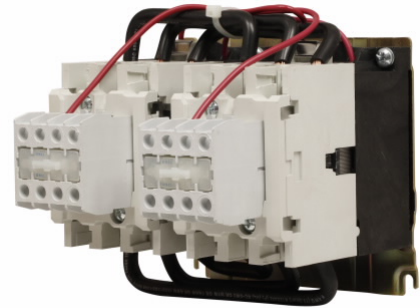

**Product compliance:**

- DIN VDE 0600
- ISO 9000

---

© 2016 Eaton. All rights reserved.