

## Eaton XT IEC contactor

**CE55NN3C**

**UPC:**782113644806

### **Dimensions:**

- **Height:** 7.17 IN
- **Length:** 5.94 IN
- **Width:** 8.16 IN

**Weight:**17 LB

**Notes:**No enclosure

### **Warranties:**

- Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

### **Specifications:**


- **Amperage Rating:** 140A
- **Coil Voltage:** 440-480 Vac, 50-60 Hz
- **Contact Configuration:** 1NO-1NC
- **Frame Size:** 250 mm
- **Frequency Rating:** 50-60 Hz
- **Mounting:** Side
- **Number Of Poles:** Three-pole
- **Operation:** Reversing
- **Relay:** No overload relay
- **Series:** Freedom
- **Type:** Contactor

### **Supporting documents:**

- [Motor Starters and Contactors - Low Voltage Catalog](#)
- [Eaton's Volume 5-Motor Control and Protection](#)
- [Eaton Specification Sheet - CE55NN3C](#)

### **Certifications:**

- UL Listed
- IEC Rated

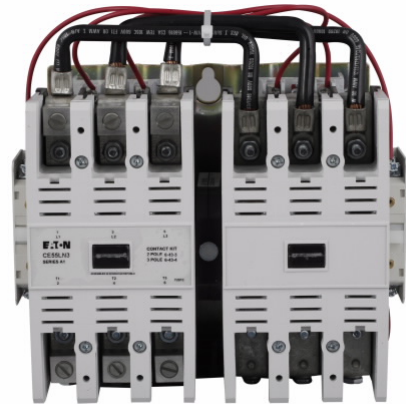

- CSA Certified

**Product compliance:**

- ISO 9000
- DIN VDE 0600

---

© 2016 Eaton. All rights reserved.