


Eaton 1224INT125B

Catalog Number: 1224INT125B

Eaton BR OEM interior assembly, BR style 1-inch loadcenter renewal part, Interior assembly, 125 A, Single-phase, 24 circuits, 12 spaces, (1) 2/0-#14 AWG Cu/Al at 60°C or 75°C, Aluminum bus

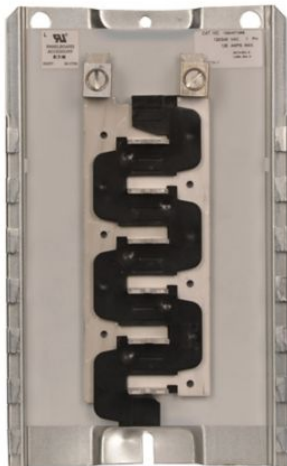

General specifications

Product Name

Eaton BR OEM interior assembly

Catalog Number

1224INT125B

UPC

786676884105

Product Length/Depth

9.25 in

Product Height

1.5 in

Product Width

5.75 in

Product Weight

0.84 lb

Warranty

Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

Compliances

Federal Specifications Classification W-P-115B, Type 1 and Class 2 Requirements

Certifications

Contact Manufacturer



Powering Business Worldwide

Product specifications

Number of spaces

12

Type

Interior assembly

Cover

Cover not included

Phase

Single-phase

Wire size

#14-2/0 AWG Cu/Al

Bus material

Aluminum

Quantity

10

Number of wires

3

Number of circuits

24

Voltage rating

120/240 V

Amperage Rating

125A

Resources

Catalogs

[Eaton's Volume 1—Residential and Light Commercial](#)

Specifications and datasheets

[Eaton Specification Sheet - 1224INT125B](#)

Warranty guides

[Selling Policy 25-000 - Distribution and Control Products and Services](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2023 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)