


Eaton CH350ST

Catalog Number: CH350ST

Eaton CH thermal magnetic circuit breaker, Type CH 3/4-Inch standard circuit breaker, 50 A, 10 kAIC, Three-pole, 240V, CH, Common breaker trip, #10-1/0 AWG Cu/Al, CH, Type CH Loadcenters, Shunt trip included

General specifications

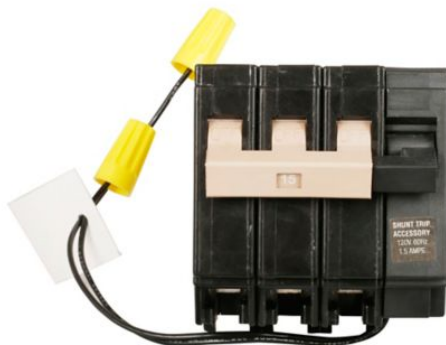

Product Name

Eaton CH thermal magnetic circuit breaker

Catalog Number

CH350ST

UPC

782113322131

Product Length/Depth

4.8 in

Product Height

3.5 in

Product Width

3.5 in

Product Weight

1.15 lb

Warranty

Limited lifetime residential, 1 year commercial

Certifications

UL 489

Catalog Notes

Three-Pole 240V Common Trip Requires Three 3/4-Inch Spaces

Product specifications

Special features

Shunt Trip

Interrupt rating

10 kAIC

Type

Type CH 3/4-Inch standard circuit breaker

Wire size

#10-1/0 AWG Cu/Al

Circuit breaker type

CH

Used with

Type CH Loadcenters

Shunt trip

Included

Main circuit breaker

CH

Voltage rating

240 V - 240 V

Amperage Rating

50 A

Trip Type

Common breaker trip

Number of poles

Three-pole

Resources

Brochures

Type CH Circuit Breakers and Loadcenters

Loadcenters and Circuit Breakers

Catalogs

Eaton's Volume 1—Residential and Light Commercial

Specifications and datasheets

Eaton Specification Sheet - CH350ST