

Eaton XT IEC contactor

XTCR009B21E

UPC:782116884797

Dimensions:

- **Height:** 5 IN
- **Length:** 5.25 IN
- **Width:** 5.75 IN

Weight:1.5 LB

Notes:Screw terminals (6-65A); 5 mm (80-150A);
no lugs (185-2000A)

Warranties:


- 1 year

Specifications:

- **Amperage Rating:** 9A
- **Coil:** 208V 60 Hz
- **Coil Voltage:** 208 Vac, 60 Hz
- **Contact Configuration:** 2NO-2NO
- **Frame Size:** 45 mm
- **Frequency Rating:** 60 Hz
- **Max Hp Rating:** 0.5, 1.5/ 3, 3, 5, 7.5 hp (1/3PH @115,230/200,230,460,575 V)
- **Number Of Poles:** Three-pole
- **Operation:** Reversing
- **Series:** XT IEC series
- **Terminals:** Screw terminals
- **Type:** Full voltage reversing contactor

Supporting documents:

- [Eaton's Volume 5-Motor Control and Protection](#)
- [XTCR_B 2D PDF](#)
- [XTCR_B 3D Model Xchange](#)
- [XTCR_B 3D Inventor](#)
- [XTCR_B 2D Drawing Xchange](#)
- [XTCR_B AutoCAD 2D Footprint \(mm\)](#)
- [XTCR_B AutoCAD 2D Footprint](#)
- [Eaton Specification Sheet - XTCR009B21E](#)

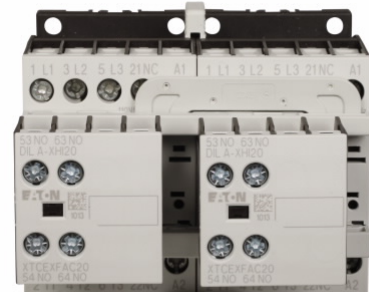

Certifications:

- CSA Certified
- UL Listed
- EN 60947
- IEC 60947

Product compliance:

- RoHS Compliant
- CE Marked

© 2016 Eaton. All rights reserved.